


nVent LENTON Speed Sleeve Transition Adaptor

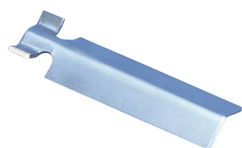

nVent LENTON Speed Sleeve Transition Adaptors allow the nVent LENTON Speed Sleeve to be used as a transition splice. The transition adaptors are simply placed inside the sleeve underneath the straps of the smaller bar end.

功能

Bars can be individually secured

Fast, one-man installation

Requires only a lightweight ratchet wrench to install

Can be used to splice two smaller bars

技术参数

完成: 普通

材料: 钢

Table 1/1

物料号	订货号	长度 (L)	宽度 (W)	单位重量
RBW3997		86mm	27 mm	0.03 kg
RBW3999	145565	86mm	38 mm	0.04 kg
RBW3998		86mm	29 mm	0.04 kg


物料号	订货号	长度 (L)	宽度 (W)	单位重量
RBW39910		111mm	38 mm	0.05 kg
RBW39911		146mm	51 mm	0.11 kg
RBW39914		152mm	57 mm	0.32 kg

其他产品详情

nVent LENTON Speed Sleeve is a compression-only splicing system. It should never be used for tension applications.

LENTON SPEED SLEEVE Transition Adaptors					
Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Sleeve	Adaptor	Adaptors Required
25 to 22 mm	#8 to #7	-	RBW2688	RBW3997	1
28 to 25 mm	#9 to #8	-	RBW2689	RBW3998	1
32 to 28 mm	#10 to #9	-	RBW26810	RBW3999	1
36 to 32 mm	#11 to #10	35M to 30M	RBW26811	RBW39910	1
43 to 36 mm	#14 to #11	45M to 35M	RBW26814	RBW39911	2
57 to 43 mm	#18 to #14	55M to 45M	RBW26818	RBW39914	2

 图



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE