


P14 Position Coupler for Cryogenic Applications

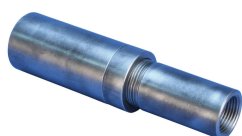

The nVent LENTON brand of cryogenic reinforcement splicing systems should be specified whenever cryogenic-grade reinforcing bar is used, or during normal operating or emergency conditions where the temperature falls below -20 °C (-4 °F). By combining the nVent LENTON taper-threaded couplers with state-of-the-art materials, we have developed one of the slimmest couplers on the market, while still maintaining top performance. Typical construction projects include LNG and LPG storage tanks.

功能

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

Improved performance and reliability at cryogenic temperatures (-168 °C / -270 °F)

技术参数

完成: 普通

材料: 不锈钢 431 (EN 1.4057)

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 1 (L1)	长度 2 (L2)
EL12P14LCRN	12 mm	#4	10M	25 mm	98 mm	103 mm
EL16P14LCRN	16 mm	#5	15M	30 mm	112 mm	117 mm
EL20P14LCRN	20 mm	#6	20M	35 mm	152 mm	161 mm


物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 1 (L1)	长度 2 (L2)
EL25P14LCRN	25 mm	#8	25M	45 mm	169 mm	178 mm
EL28P14LCRN	28 mm	#9	30M	50 mm	175 mm	184 mm
EL32P14LCRN	32 mm	#10		60 mm	192 mm	201 mm

Table 2/2					
物料号	杆深 (BD)	杆间隙 1 (BG1)	杆间隙 2 (BG2)	联轴器主体 (CB)	单位重量
EL12P14LCRN	19mm	60mm	65mm	46mm	0.12 kg
EL16P14LCRN	24mm	64mm	69mm	54mm	0.18 kg
EL20P14LCRN	35mm	82mm	91mm	76mm	0.33 kg
EL25P14LCRN	40mm	89mm	98mm	86mm	0.62 kg
EL28P14LCRN	42mm	91mm	100mm	90mm	0.81 kg
EL32P14LCRN	45mm	102mm	111mm	96mm	1.34 kg

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

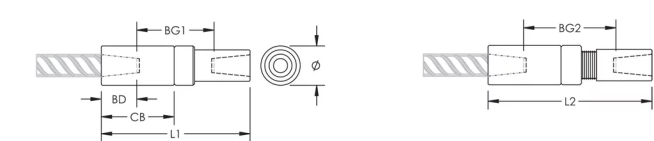

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE