


P24 Position Coupler

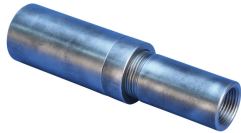

The P24 family of position couplers is designed for use on ASTM A615 grade 100 (700 MPa) reinforcing steel. The performance of the spliced connection is designed to meet the bars' specified ultimate tensile strength of 115 ksi (792 MPa).

功能

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

技术参数

完成: 普通

材料: 钢

100% 美国国内内容: 是

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 1 (L1)	长度 2 (L2)
EL22P24L	22 mm	#7		44 mm	172 mm	188 mm
EL25P24L	25 mm	#8	25M	48 mm	183 mm	199 mm
EL28P24L	28 mm	#9	30M	57 mm	192 mm	208 mm
EL32P24L	32 mm	#10		60 mm	208 mm	224 mm


物料号	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大	直径 (Ø)	长度 1 (L1)	长度 2 (L2)
EL36P24L	36 mm	#11	35M	70 mm	227 mm	243 mm
EL43TP24L	43 mm	#14	45M	80 mm	296 mm	324 mm
EL57TP24L	57 mm	#18	55M	102 mm	347 mm	375 mm

Table 2/2					
物料号	杆深 (BD)	杆间隙 1 (BG1)	杆间隙 2 (BG2)	联轴器主体 (CB)	单位重量
EL22P24L	37mm	98mm	114mm	92mm	1.55 kg
EL25P24L	40mm	103mm	119mm	98mm	1.87 kg
EL28P24L	42mm	108mm	124mm	104mm	2.85 kg
EL32P24L	45mm	118mm	134mm	110mm	3.39 kg
EL36P24L	52mm	124mm	140mm	120mm	5.1 kg
EL43TP24L	66mm	164mm	192mm	160mm	8.3 kg
EL57TP24L	83mm	180mm	208mm	188mm	15.5 kg

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

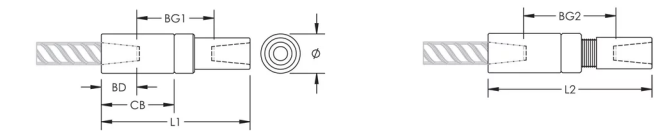

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE