

P9J Weldable Position Coupler



功能

Designed for connecting reinforcing bar perpendicular to structural steel sections or plates when the mating bar cannot be rotated and is free to move in its axial direction

Ideal for connecting hooked reinforcing bar to structural steel elements

Internally taper threaded on one end, with the other end prepared for welding

Machined from weldable grades of steel

技术参数

完成: 普通

材料: 钢

100% 美国国内内容: 是

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)	长度 1 (L1)
EL20P9J	20 mm	#6	20M	51 mm	41 mm	105 mm
EL22P9J	22 mm	#7		51 mm	38 mm	110 mm
EL25P9J	25 mm	#8	25M	51 mm	35 mm	115 mm


物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)	长度 1 (L1)
EL28P9J	28 mm	#9	30M	76 mm	64 mm	114 mm
EL32P9J	32 mm	#10		76 mm	60 mm	120 mm
EL36P9J	36 mm	#11	35M	76 mm	57 mm	126 mm

Table 2/2				
物料号	长度 2 (L2)	杆深 (BD)	联轴器主体 (CB)	单位重量
EL20P9J	114 mm	28mm	65mm	1.18 kg
EL22P9J	118 mm	32mm	70mm	1.22 kg
EL25P9J	123 mm	34mm	75mm	1.22 kg
EL28P9J	121 mm	38mm	73mm	2.72 kg
EL32P9J	128 mm	40mm	80mm	2.77 kg
EL36P9J	134 mm	43mm	86mm	2.9 kg

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

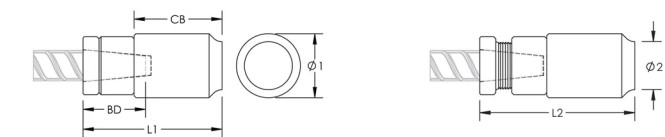

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE