

S13 Metric Parallel Bolt Coupler, Stainless Steel



Stainless steel couplers are specified whenever corrosive environmental conditions combine with the need for high load-bearing strength. nVent LENTON stainless steel couplers are commonly used when the construction materials may come into contact with de-icing salts, salt water or marine environments. Typical applications include bridges and bridge decks.

功能

Provides continuity between reinforcing bar and ISO® 965 metric all-thread rod or bolts

May be used to anchor load-bearing equipment to foundations, columns or walls

Machined from non-weldable grades of material, but can be tack welded

技术参数

完成: 普通
材料: 双相不锈钢 2205 (EN 1.4462)
设计版本: 全球 (全球可供货的材料)

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 (L)	A
EL12S13SSN	12 mm	#4	10M	25.4 mm	58mm	33 mm
EL16S13SSN	16 mm	#5	15M	30 mm	68mm	37 mm
EL20S13SSN	20 mm	#6	20M	35 mm	98mm	55 mm

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 (Ø)	长度 (L)	A
EL25S13SSN	25 mm	#8	25M	45.8 mm	110mm	61 mm
EL32S13ASSN	32 mm	#10		55 mm	128mm	73 mm
EL32S13SSN	32 mm	#10		55 mm	125mm	70 mm

Table 2/2				
物料号	杆深 (BD)	螺纹尺寸 (TS)	螺纹深度 (TD)	单位重量
EL12S13SSN	19mm	M16	19mm	0.16 kg
EL16S13SSN	24mm	M20	23mm	0.49 kg
EL20S13SSN	35mm	M24	27mm	0.63 kg
EL25S13SSN	40mm	M30	33mm	0.92 kg
EL32S13ASSN	45mm	M42	46mm	1.3 kg
EL32S13SSN	45mm	M39	43mm	1.46 kg

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Coupler supplied without bolt.

Bolt may be replaced by threaded rod of same class/grade.


All calculations based on a minimum bolt engagement equal to Thread Depth (TD).

System Capacity based on bolt to coupler connection. For rebar to coupler connection, refer to applicable building codes and approvals or contact your nVent LENTON representative.

Suffix "EE" has been added to some part numbers to clarify design version among regions.

Bolt-to-Coupler Capacity (kN)					
Part Number	Grade 4.8	Grade 5.8	Grade 8.8	Grade 10.9	Grade 12.9
EL12S13SSN	62.7	78.3	109.8	109.8	109.8
EL16S13SSN	97.9	122.4	162.9	162.9	162.9
EL20S13SSN	141	176.3	282	332.3	332.3
EL25S13SSN	224.2	280.3	448.5	560.5	560.5
EL32S13ASSN	448.4	560.5	896.7	1120.9	1197.1
EL32S13SSN	390.3	487.9	780.6	783.8	783.8

图

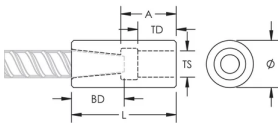

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE