

T-Series Horizontal Sleeve, Top Fill



The top fill horizontal T-Series sleeve has vent holes to reduce air entrapment and help ensure proper filling of the sleeve.

功能

Designed to connect horizontal reinforcing bars and angular reinforcing bars up to 45 degrees

Used to splice the same diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

技术参数

完成: 普通

材料: 钢

100% 美国国内内容: 是

Table 1/2

物料号	套管	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)
RBT6101HA	标准长度	20 mm	#6	20M	38 mm	25 mm
RBT51012HA	加长长度	16 mm	#5	15M	35 mm	22 mm
RBT7101HA	标准长度	22 mm	#7		41 mm	29 mm

物料号	套管	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大	直径 1 (Ø1)	直径 2 (Ø2)
RBT1091HA	标准长度	32 mm	#10		57 mm	41 mm
RBT11101HA	标准长度	36 mm	#11	35M	64 mm	44 mm
RBT61012HA	加长长度	20 mm	#6	20M	38 mm	25 mm
RBT81011HA	加长长度	25 mm	#8	25M	48 mm	32 mm
RBT81012HA	加长长度	25 mm	#8	25M	48 mm	32 mm
RBT8101HA	标准长度	25 mm	#8	25M	48 mm	32 mm
RBT91012HA	加长长度	28 mm	#9	30M	54 mm	38 mm
RBT9101HA	标准长度	28 mm	#9	30M	54 mm	38 mm
RBT71011HA	加长长度	22 mm	#7		41 mm	29 mm
RBT10911HA	加长长度	32 mm	#10		57 mm	41 mm
RBT111011HA	加长长度	36 mm	#11	35M	64 mm	44 mm
RBT111012HA	加长长度	36 mm	#11	35M	64 mm	44 mm
RBT121018HA	加长长度	38 mm	#12		70 mm	48 mm
RBT12917HA	标准长度	38 mm	#12		70 mm	48 mm
RBT141011HA	加长长度	43 mm	#14	45M	76 mm	54 mm
RBT14101HA	标准长度	43 mm	#14	45M	76 mm	54 mm

物料号	套管	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)
RBT1891HA	标准长度	57 mm	#18	55M	95 mm	67 mm
RBT91011HA	加长长度	28 mm	#9	30M	54 mm	38 mm

Table 2/2				
物料号	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	单位重量
RBT6101HA	127 mm	64 mm	20mm	0.63 kg
RBT51012HA	152 mm	76 mm		0.68 kg
RBT7101HA	127 mm	64 mm	20mm	0.69 kg
RBT1091HA	140 mm	70 mm	20mm	1.34 kg
RBT11101HA	152 mm	76 mm	20mm	1.93 kg
RBT61012HA	178 mm	89 mm	20mm	0.88 kg
RBT81011HA	152 mm	76 mm	20mm	1.38 kg
RBT81012HA	203 mm	89 mm	20mm	1.38 kg
RBT8101HA	127 mm	64 mm	20mm	0.98 kg
RBT91012HA	178 mm	89 mm	20mm	1.6 kg
RBT9101HA	127 mm	64 mm	20mm	1.14 kg
RBT71011HA	152 mm	76 mm	26mm	0.83 kg
RBT10911HA	165 mm	83 mm	26mm	1.59 kg

物料号	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	单位重量
RBT111011HA	178 mm	89 mm	26mm	2.25 kg
RBT111012HA	203 mm	102 mm	26mm	2.57 kg
RBT121018HA	203 mm	102 mm	26mm	3.27 kg
RBT12917HA	178 mm	89 mm	26mm	2.86 kg
RBT141011HA	203 mm	102 mm	26mm	3.62 kg
RBT14101HA	178 mm	89 mm	26mm	3.17 kg
RBT1891HA	229 mm	114 mm	26mm	6.51 kg
RBT91011HA	152 mm	76 mm	26mm	1.37 kg


其他产品详情

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

RBT51012HA does not have vent holes.

图

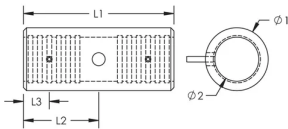

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE