

T-Series Vertical Low Slip Sleeve



The low slip vertical T-Series sleeve's increased sleeve length reduces slip (for extreme code requirements) and improves splice performance when the rib pattern or spacing does not meet the minimum product specifications.

功能

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice the same diameter bars

Additional length improves performance

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

技术参数

完成: 普通

材料: 钢

100% 美国国内内容: 是

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)	长度 1 (L1)
RBW6555A	16 mm	#5	15M	35 mm	22 mm	152 mm
RBW6556A	20 mm	#6	20M	38 mm	25 mm	178 mm
RBW6557A	22 mm	#7		41 mm	29 mm	178 mm

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)	长度 1 (L1)
RBW6558A	25 mm	#8	25M	48 mm	32 mm	178 mm
RBW6559A	28 mm	#9	30M	54 mm	38 mm	178 mm
RBW65510A	32 mm	#10		57 mm	41 mm	191 mm
RBW65511A	36 mm	#11	35M	64 mm	44 mm	203 mm
RBW65514A	43 mm	#14	45M	76 mm	54 mm	229 mm
RBW65518A	57 mm	#18	55M	95 mm	67 mm	279 mm


Table 2/2		
物料号	长度 2 (L2)	单位重量
RBW6555A	76 mm	0.68 kg
RBW6556A	89 mm	0.86 kg
RBW6557A	89 mm	0.95 kg
RBW6558A	89 mm	1.36 kg
RBW6559A	89 mm	1.6 kg
RBW65510A	95 mm	1.81 kg
RBW65511A	102 mm	2.54 kg
RBW65514A	114 mm	4.04 kg
RBW65518A	140 mm	7.94 kg

其他产品详情

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

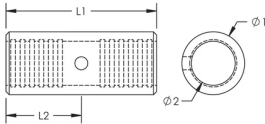

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE