

# Copper-Bonded Ground Rod, Pointed

## Power Utilities



### 功能

99.9% pure electrolytic copper coating

Rods have a high carbon steel core and tip that provide superior strength when driving

Copper coating will not crack when bent or tear when driven

Minimum copper coating of 10 mils on rods listed to UL® 467

nVent ERICO name, length, diameter and part number is roll-stamped within 12" (304,8 mm) of chamfered end

UL logo and control number where applicable stamped on each rod for easy inspection after installation

### 技术参数

Table 1/1

| 物料号    | 抗拉强度        | 接地棒标称直径 | 接地棒实际直径<br>(Ø) | 镀层厚度   | 单位重量     | UPC 标签 |
|--------|-------------|---------|----------------|--------|----------|--------|
| 611330 | 552 MPa Min | 1/2"    | 12.8 mm        | 254 µm | 0.980 kg | 否      |


其他产品详情

For rods to be listed to UL® 467, they must be at least 8' (2.44 m) in length.

IEC® EN 62561-2 supercedes EN 50164-2.

Additional lengths available.

图

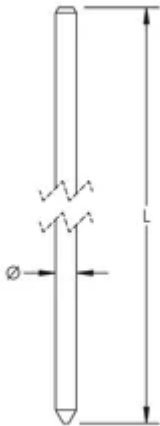

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

⚠ WARNING: This product can expose you to chemicals including nickel, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE