


EuropacPRO Cover Plate for Bolting to Rugged Side Panel, 84 HP, 275 mm

Power Utilities

物料号

24568-032

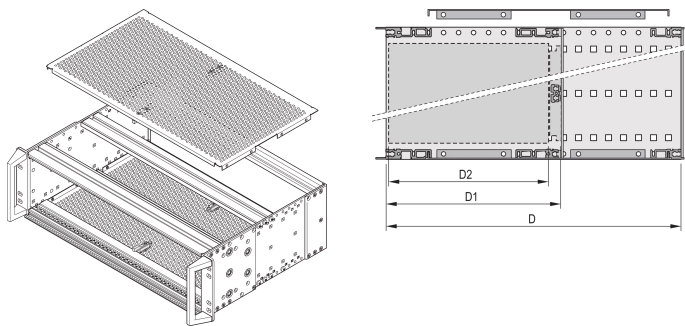

A cover plate is used for electromagnetic shielding or as mechanical protection.

认证



功能

Perforation degree 58%

产品属性

产品类型: 盖板

产品系列: EuropacPRO

类型: 穿孔

机架宽度: 84 HP

深度: 275 mm

包装数量: 1

包装单位: 对

扭矩: 2.1 N • m

其他产品详情

A top cover locking mechanism is optionally available that also fixes the top cover in the front and rear guide rail.

4 stainless steel EMC contact strips per subrack are required for shielding, please order separately.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE