


Horizontal Rail, Front, Type L-KD, Light, Short Lip, 84 HP

Power Utilities

物料号

34560-184

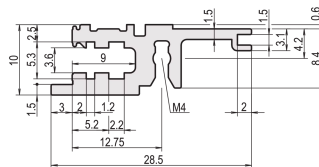

Combinations of horizontal rails and side panels

“+” can be combined, “-” combination not recommended

	Standard rail	Standard rail with short lip (L-KD)	Standard rail with short lip (L-KD) with short lip (L-KD)	Standard rail with short lip (L-KD) with short lip (L-KD) with short lip (L-KD)
Standard rail	-	+	+	+
Standard rail with short lip (L-KD)	+	+	+	+
Standard rail with short lip (L-KD) with short lip (L-KD)	+	+	-	-
Standard rail with short lip (L-KD) with short lip (L-KD) with short lip (L-KD)	+	+	-	-

Side panel

Light 1.1, Standard 1.1, Heavy 1.1, Rugged 1.1

The horizontal rail with a short lip makes a clean design to the assembled front panel.

认证



功能

Standard rail at the front

Installation at top and bottom

Short lip (L-KD)

< 28 HP not to print

Aluminum extrusion, anodized finish, conductive contact surface

产品属性

产品类型: 水平横梁

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

类型: 轻型, KD

机架宽度: 84 HP

长度: 431.8 mm

包装数量: 1

其他产品详情

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE