


EuropacPRO Rear Hood for Stainless Steel EMC Gasket

Power Utilities

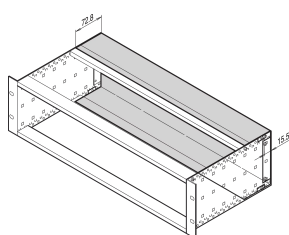

The rear hood is used as a shielded rear boundary and requires 60 mm space. Therefore if the rear hood is used, the side panel depth must be 60 mm greater than the board depth. Contact between the rear hood and the horizontal rails is established by the stainless steel contact strip for the cover plate. Thus no additional EMC sealing is necessary. Rear hood cannot be used simultaneously with rear corner profile.

认证



功能

The rear hood is used as a shielded rear boundary. The rear hood requires 60 mm space. Therefore if the rear hood is used, the side panel depth must be 60 mm greater than the board depth. Example: For a board depth of 160 mm a side panel (with rear hood) of 235 mm (175 mm + 60 mm) is used

Contact between the rear hood and the horizontal rails is established by the stainless steel contact strip for the cover plate. Thus no additional EMC sealing is necessary

Rear hood cannot be used simultaneously with rear corner profile

For EMC-shielding please order EMC gasket for horizontal rail separately.

技术参数

Table 1/2

物料号	机架高度	机架宽度	包装数量	产品系列	产品类型	类型
-----	------	------	------	------	------	----

34561-763	6 U	63 HP	1	EuropacPRO	盖板	后罩
34561-752	3 U	84 HP	1	EuropacPRO	盖板	后罩
34561-750	3 U	42 HP	1	EuropacPRO	盖板	后罩
34561-764	6 U	84 HP	1	EuropacPRO	盖板	后罩

Table 2/2	
物料号	搭配
34561-763	插箱
34561-752	插箱
34561-750	插箱
34561-764	插箱

其他产品详情

Required quantity of screws per rear hood: 3 U subrack 10 screws; 6 U subrack 16 screws.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE