


FBC nVent ERIFLEX Flexibar/Cable to Busbar Clamp

Power Utilities

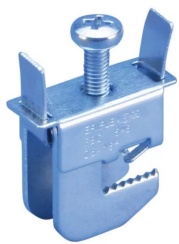

认证



功能

Very compact clamp for connecting cable conductors or nVent ERIFLEX Flexibar to busbar without drilling

Conductor is clamped with a pressure plate

Clamps can be mounted and slid into position on busbar prior to connecting conductors

Connections can be added after busbar has been mounted

Single screw locks clamp and makes connection

EAC compliant

RoHS compliant


技术参数

Table 1/1						
物料号	订货号	母排厚度	导体宽度	高度 (H)	宽度 (W)	单位重量
FBC10X15-5	553530	10 mm	15.5 mm	49 mm	40 mm	0.112 kg

其他产品详情

Conductor must be stripped at least a distance equal to the width of the clamp.

图

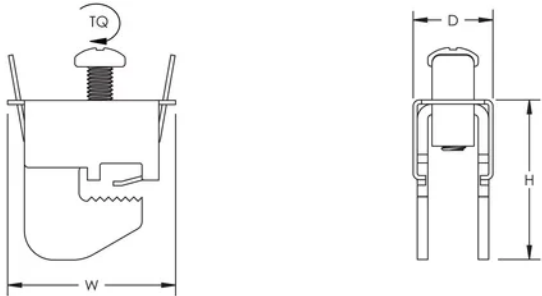

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE