


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

Power Utilities

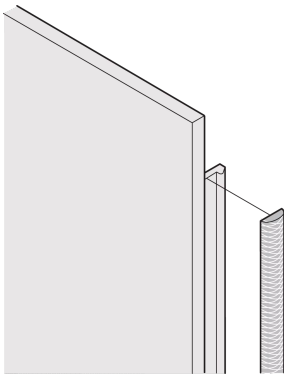

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

认证



功能

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

技术参数

Table 1/1

物料号	机架高度	包装数量	产品系列	产品类型	搭配
-----	------	------	------	------	----

21101-857	2 U	10	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-854	3 U	100	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-853	3 U	10	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-858	4 U	10	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-978	5 U	10	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-855	6 U	10	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-856	6 U	100	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
21101-859	9 U	10	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板

21101-904	9 U	100	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, PropacPRO, 框架式插入单元	屏蔽套件	插箱, 仪器箱, 前面板
-----------	-----	-----	--	------	-----------------

其他产品详情

EMC gaskets (textile) are required for shielding the front panels.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE