

UFS nVent ERIFLEX Flexibar and IBSB Support Kit

Power Utilities



认证



功能

Kit includes one rail and 24 retaining blocks

Create up to three 650 mm (25.6") supports capable of holding four nVent ERIFLEX Flexibar

Retaining blocks are halogen free

RoHS compliant

技术参数

Table 1/2

物料号	订货号	导体厚度	导体宽度	高度 (H)	宽度 (W)	A
-----	-----	------	------	--------	--------	---


UFS-KIT	553590	2 – 8 mm	15.5 – 120.0 mm	57.50 mm	30 mm	24 mm
---------	--------	----------	-----------------	----------	-------	-------

Table 2/2			
物料号	订货号	B	单位重量
UFS-KIT	553590	15 mm	2.300 kg

其他产品详情

Recommended distance between supports is 400 mm (15 3/4").

图

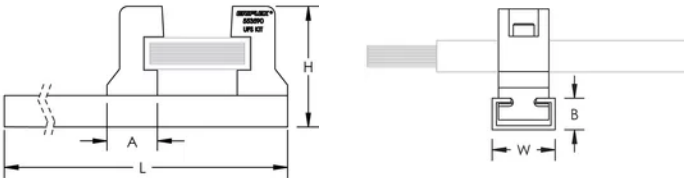

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE