


带 SUB-D 开孔的 19" 前面板

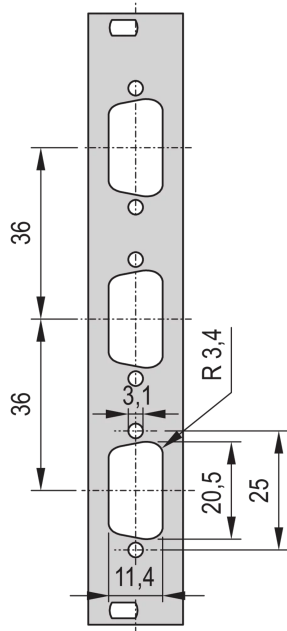

19" 前面板，带 SUB-D 开孔或 FDDI 开孔。

认证



功能


19 英寸前面板，带 Sub-D 开孔, ST 类型 3 或 FDDI

技术参数

深度 (D):	2.5mm
材料:	铝
附件类型:	前面板
产品类型:	前面板

Table 1/2						
物料号	机架高度	机架宽度	包装数量	正面表面处理	反面表面处理	引脚数
30118-332	3U	4HP	1	涂漆	导电	(3) 9
30118-334	3U	4HP	1	涂漆	导电	(1) 25
30118-336	3U	4HP	1	涂漆	导电	(2) 9
30118-338	3U	4HP	1	涂漆	导电	(1) 9
30118-335	3U	4HP	1	涂漆	导电	(2) 25

Table 2/2					
物料号	颜色代码	完成	高度 (H)	宽度 (W)	快速发货
30118-332	RAL 7035	粉末涂层	128.4mm	19.98mm	No
30118-334	RAL 7035	粉末涂层	128.4mm	19.98mm	No
30118-336	RAL 7035	粉末涂层	128.4mm	19.98mm	No
30118-338	RAL 7035	粉末涂层	128.4mm	19.98mm	No
30118-335	RAL 7035	粉末涂层	128.4mm	19.98mm	No

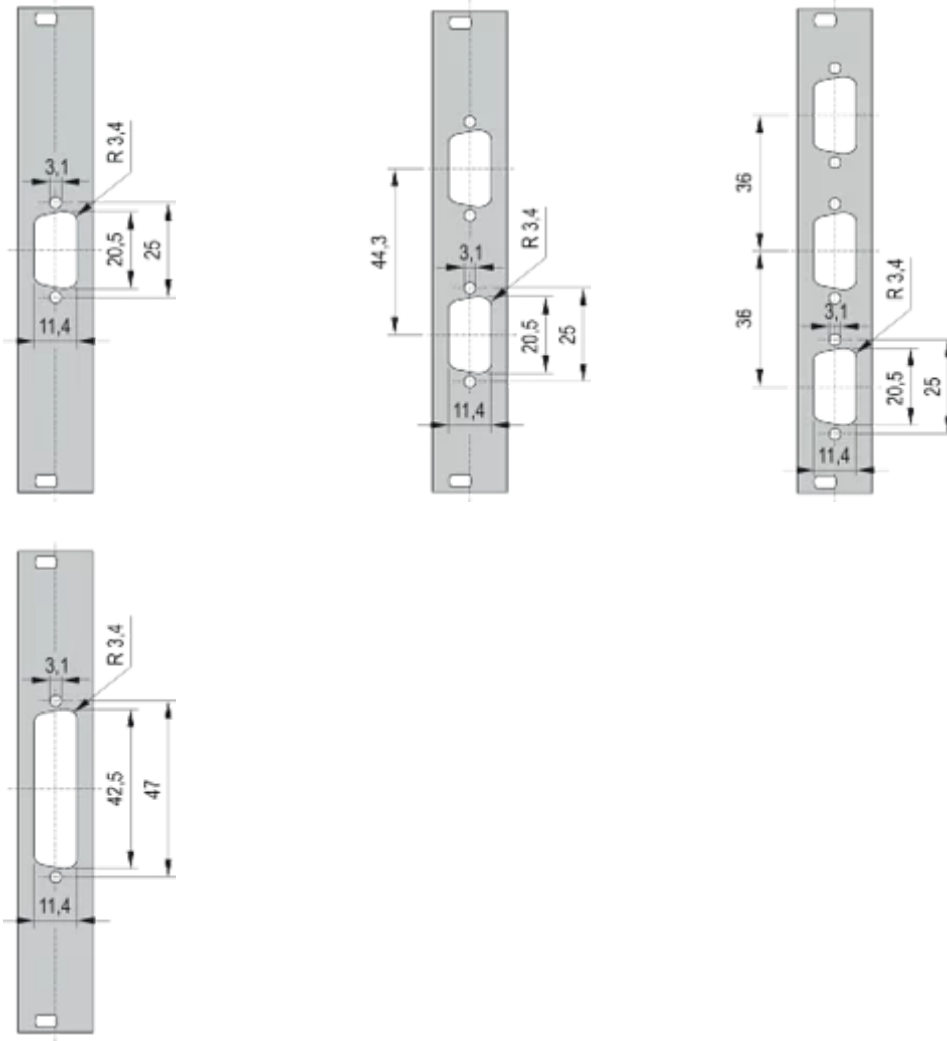

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE