


适用于 AMC 填充模块的空气挡板

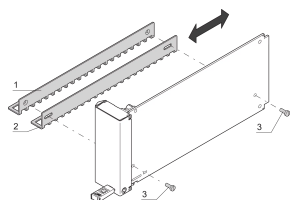

带空气挡板和推-拉式把手的填充模块可将气流引向带 AdvancedMC 模块的插槽，以确保正确冷却。空气挡板由固定和可移动部件组成，用于在 60 至 80 % 的范围内调节穿过插槽的气流。

认证



功能

可改装为 AMC 填充模块

气流可调节，用于阻挡气流穿过未使用的插槽

空气挡板由固定和可移动部件组成，用于在 60 至 80% 的范围内调节穿过插槽的气流

技术参数

类型:	AdvancedMC 填充模块
产品类型:	空气挡板
材料:	铝
产品系列:	MicroTCA
搭配:	系统

Table 1/1

物料号	设计特征	包装数量	快速发货
20849-016	紧凑型	10	No

物料号	设计特征	包装数量	快速发货
20849-017	中尺寸	10	No
20849-018	全尺寸	10	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE