


不带前面板的空气挡板

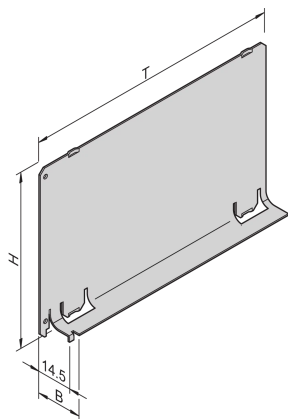

不带部分前面板的空气挡板可与覆盖完整宽度的前面板组合。它可以覆盖空插槽，以防空气泄漏。

认证



功能

空气挡板可以防止空插槽漏气

安装方式，按压上盖推入到导轨中

技术参数

产品类型: 空气挡板

材料: 铝

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

类型: 无前面板

Table 1/1

物料号	机架高度	包装数量	深度	机架宽度	搭配	快速发货
-----	------	------	----	------	----	------

34562-823	3U	1	160mm	4HP	插箱, 仪器箱	No
34562-824	3U	1	220mm	4HP	插箱, 仪器箱	No
34562-826	6U	1	160mm	4HP	插箱, 仪器箱	No
34562-827	6U	1	220mm	4HP	插箱, 仪器箱	No

其他产品详情

可应要求提供适用 280 mm 深度和 80 mm 后部 I/O 板的空气挡板。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE