


带拉杆把手的 AMC 模块, AMC.0 R2.0

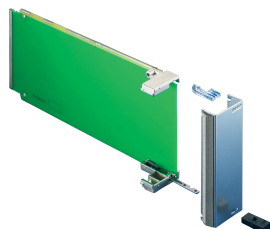

AdvancedMC 前面板，包括适用 AMC.0 2.0 修订版标准模块的把手机构和 EMC 垫片。

认证



功能

符合 AMC.0 R2.0 技术参数

适合安装在 MicroTCA 机箱或 AdvancedMC 载板上（例如，传统载板, 分割式载板和混合配置载板）

技术参数

产品系列: AdvancedMC

类型: 填充模块

产品类型: 系统模块

Table 1/1

物料号	高度	设计特征	材料	完成	包装数量	快速发货
20849-268	73.8mm	中尺寸	铝	钝化	1	No
20849-127	73.8mm	紧凑型	不锈钢		1	No

物料号	高度	设计特征	材料	完成	包装数量	快速发货
20849-270	73.8mm	全尺寸	铝	钝化	1	No
20849-128	73.8mm	中尺寸	不锈钢		1	No
20849-129	73.8mm	全尺寸	不锈钢		1	No
20849-269	148.8mm	中尺寸	铝	钝化	1	No
20849-271	148.8mm	全尺寸	铝	钝化	1	No
20849-131	148.8mm	中尺寸	不锈钢		1	No
20849-132	148.8mm	全尺寸	不锈钢		1	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE