


ATCA 前面板, 铝制型材, Reinforced With Spring Loading

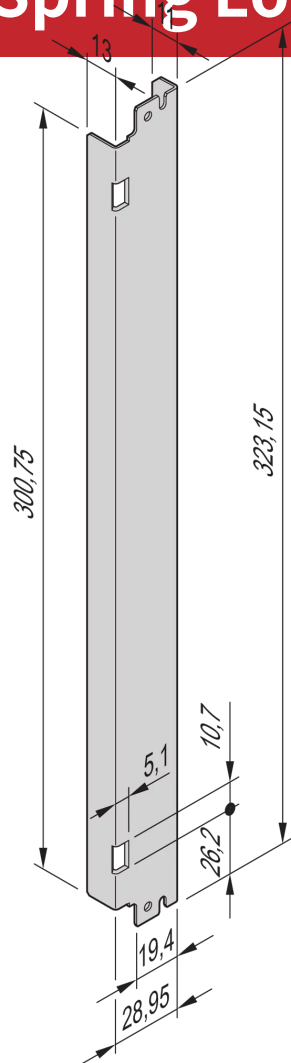

AdvancedTCA 前面板，适用于带压铸尾端件的弹簧 IEA 把手。

认证



功能

配置：带 IEA 把手的前面板（带/不带弹簧承载装置）


铝挤压件；适用于网状 EMC 密封件

技术参数

- 深度 (D): 1mm
- 机架宽度: 6HP
- 机架高度: 8U
- 材料: 铝
- 附件类型: 前面板
- 产品类型: 前面板

Table 1/2						
物料号	包装数量	手柄类型	正面表面处理	反面表面处理	完成	高度 (H)
31596-900	1	拨杆	未加工	未加工	钝化	323.15mm
31596-899	1	柱塞	未加工	未加工	钝化	323.15mm

Table 2/2		
物料号	宽度 (W)	快速发货
31596-900	29mm	No
31596-899	29mm	No

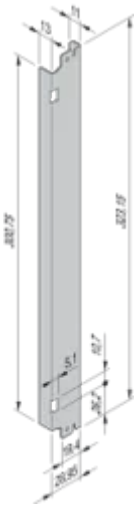

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE