


带直通信号线的背板

带直通信号线的背板。

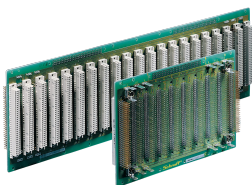

认证



功能

电源在每个连接器的第 1 排 + 32

2 层背板, 含电源连接的适配区域

技术参数

Table 1/2

物料号	产品类型	插槽数	机架高度	背板类型	槽宽	连接器类型
23007-188	背板	28	3U	60 信号线	3HP	
23007-010	背板	10	3U	60 信号线	4HP	C64F
23007-081	背板	21	3U	60 信号线	4HP	
23007-114	背板	14	3U	60 信号线	3HP	C64F

物料号	产品类型	插槽数	机架高度	背板类型	槽宽	连接器类型
23007-040	背板	10	3U	60 信号线	4HP	C96F
23007-410	背板	10	3U	90 信号线	4HP	C96F
23007-021	背板	21	3U	60 信号线	4HP	C64F
23007-421	背板	21	3U	90 信号线	4HP	C96F
23007-051	背板	21	3U	60 信号线	4HP	C96F
23007-128	背板	28	3U	60 信号线	3HP	C64F
23007-158	背板	28	3U	60 信号线	3HP	C96F

Table 2/2			
物料号	电源连接器类型	包装数量	快速发货
23007-188	紧固件 6.3 x 0.8 mm	1	No
23007-010	紧固件 6.3 x 0.8 mm	1	No
23007-081	紧固件 6.3 x 0.8 mm	1	No
23007-114	紧固件 6.3 x 0.8 mm	1	No
23007-040	紧固件 6.3 x 0.8 mm	1	No
23007-410	紧固件 6.3 x 0.8 mm	1	No
23007-021	紧固件 6.3 x 0.8 mm	1	No
23007-421	紧固件 6.3 x 0.8 mm	1	No

物料号	电源连接器类型	包装数量	快速发货
23007-051	紧固件 6.3 x 0.8 mm	1	No
23007-128	紧固件 6.3 x 0.8 mm	1	No
23007-158	紧固件 6.3 x 0.8 mm	1	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE