


# C-Profile Adaptor for Subracks Assembled into Cabinets

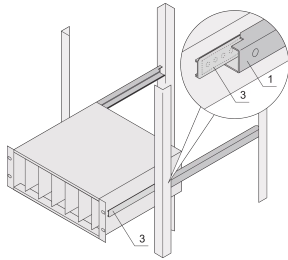

安装到机柜中时，插箱侧板上装配的 C 型材可将插箱固定在导向型材上。

## 认证



## 功能

安装到机柜中时，C 型材可将插箱固定在导向型材上。

## 技术参数

材料: 铝  
完成: 阳极氧化  
产品系列: EuropacPRO  
产品类型: 伸缩滑轨

Table 1/1

| 物料号       | 深度    | 包装数量 | 搭配 | 快速发货 |
|-----------|-------|------|----|------|
| 24562-453 | 175mm | 2    | 插箱 | No   |

| 物料号       | 深度    | 包装数量 | 搭配 | 快速发货 |
|-----------|-------|------|----|------|
| 24562-454 | 235mm | 2    | 插箱 | No   |
| 24562-455 | 295mm | 2    | 插箱 | No   |
| 24562-456 | 355mm | 2    | 插箱 | No   |
| 24562-457 | 415mm | 2    | 插箱 | No   |
| 24562-458 | 475mm | 2    | 插箱 | No   |

其他产品详情

注意：插箱拉出时，末端无停止装置。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE