


Novastar 和 Eurorack 走线板

封闭半高矮门或后面板上的开口，使外表更加美观。

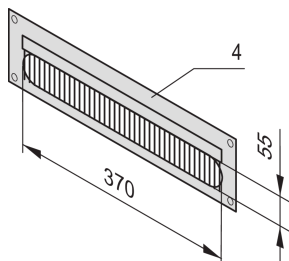

认证



功能

用于封闭半高矮门或后面板上的开口

框架, 碳钢, 2.5 mm

带黑色毛刷

技术参数

产品类型: 盖板

Table 1/2

物料号	机架高度	颜色	设计特征	包装数量	颜色代码	完成
27230-160	3U	暗灰色	刷	1	RAL 7021	阳极氧化
27230-161	4U	暗灰色	刷	1	RAL 7021	阳极氧化
20118-390	4U	浅灰色	面板和刷	1	RAL 7035	粉末涂层

物料号	机架高度	颜色	设计特征	包装数量	颜色代码	完成
20118-391	3U	浅灰色	面板和刷	1	RAL 7035	粉末涂层

Table 2/2			
物料号	材料	类型	快速发货
27230-160	铝	电缆管道	No
27230-161	铝	电缆管道	No
20118-390	钢	电缆管道	No
20118-391	钢	电缆管道	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE