


编码条

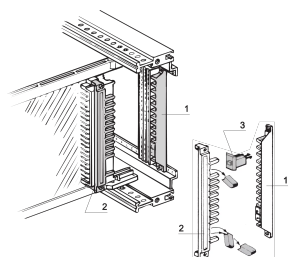

编码安装在连接器侧面。通过编码，只有编码板才能放入正确的插槽中。

认证



功能

机械编码可防止 PSU 安装在错误的插槽上, 空间要求 4 HP

母带 (2 项) , 安装在 PSU 上

编码带 (第 1 项) 安装在 Z/水平轨道上

编码引脚 (第 3 项) 安装在编码带 (第 1 项) 上

拆除母带中适当位置的螺柱

通过 2 编码引脚, 有 66 种编码可能性

技术参数

搭配: 19" 电源

类型: 编码条

产品类型: 编码/键控指示器

材料: 聚对苯二甲酸丁二醇酯

Table 1/1

物料号	包装数量	引脚数	认证	快速发货
-----	------	-----	----	------

60800-123	1	(1) 2	RoHS	No
60800-122	1			No

其他产品详情

编码带；编码块；键控带

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE