


凸缘螺钉, 十字槽/开槽

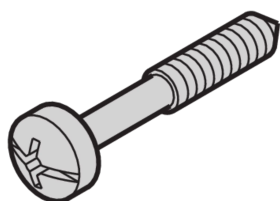

认证



技术参数

产品类型: 螺钉
类型: 螺钉

Table 1/3

物料号	直径	长度	材料	完成	包装数量	螺纹尺寸
21101-102		12.3mm	钢	锌面涂层	100	M2.5
21101-906		12.3mm	不锈钢		100	M2.5
21101-323		11mm			100	M2.5
21102-026	2.5mm	12.3mm	钢	镀镍	100	M2.5
21101-101		12.3mm	钢	镀镍	100	M2.5

Table 2/3						
物料号	深度	高度	宽度	搭配	螺纹类型	扭矩
21101-102	14.3mm	5mm	5mm	前面板	公制	0.3N • m
21101-906				前面板		0.3N • m
21101-323				前面板		
21102-026				框架式插入单元 ， 模块盒		0.3N • m
21101-101	14.3mm	5mm	5mm	前面板	公制	0.3N • m

Table 3/3		
物料号	认证	快速发货
21101-102	RoHS	No
21101-906	RoHS	No
21101-323		No
21102-026		No
21101-101	RoHS	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE