


CompacPRO 面板

CompacPRO 机箱的前面板通过螺栓连接至机箱前框架。

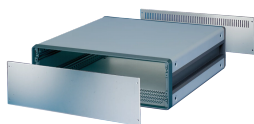

认证



功能

前面板用螺栓固定在机箱的前框架上

技术参数

材料: 铝
完成: 阳极氧化
附件类型: 前面板
产品类型: 前面板

Table 1/2

物料号	机架高度	机架宽度	深度	包装数量	正面表面处理	反面表面处理
30823-209	2U	42HP	3mm	1	阳极氧化	阳极氧化
30823-254	3U	28HP	3mm	1	阳极氧化	阳极氧化

物料号	机架高度	机架宽度	深度	包装数量	正面表面处理	反面表面处理
30823-257	3U	42HP	3mm	1	阳极氧化	阳极氧化
30823-215	2U	84HP	3mm	1	阳极氧化	阳极氧化
30823-269	4U	42HP	3mm	1	阳极氧化	阳极氧化
30823-224	3U	63HP	3mm	1	阳极氧化	阳极氧化
30823-260	3U	84HP	3mm	1	阳极氧化	阳极氧化
30823-227	4U	63HP	3mm	1	阳极氧化	阳极氧化
30823-272	4U	84HP	3mm	1	阳极氧化	阳极氧化
30823-230	6U	63HP	3mm	1	阳极氧化	阳极氧化
30823-284	6U	84HP	3mm	1	阳极氧化	阳极氧化

Table 2/2					
物料号	边缘处理	EMC 屏蔽	高度	宽度	快速发货
30823-209	否	否	84mm	238.7mm	No
30823-254	否	否	128.4mm	167.5mm	No
30823-257	否	否	128.4mm	238.7mm	No
30823-215	否	否	84mm	452.1mm	No
30823-269	否	否	1729mm	238.7mm	No
30823-224	否	否	128.4mm	345.4mm	No

物料号	边缘处理	EMC 屏蔽	高度	宽度	快速发货
30823-260	否	否	128.4mm	452.1mm	No
30823-227	否	否	172.9mm	345.4mm	No
30823-272	否	否	172.9mm	452.1mm	No
30823-230	否	否	261.8mm	345.4mm	No
30823-284	否	否	261.8mm	452.1mm	No

其他产品详情

仪器箱中包含用于固定一个后面板和一个前面板的装配套件。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE