


适于 MicroTCA 的 PSU 19 英寸 AC/DC，带管理 (PM EMMC) 双全尺寸

物料号

11098-547

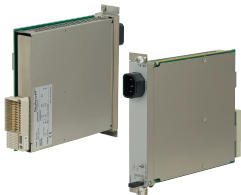

MTCA PSU 600 是非常高效的电源模块 (PM)，适用 MicroTCA 应用。这款 600W 电源是最高效的 Double Full-Size 电源。这款电源模块带有集成管理控制器，非常适用于运行最新一代处理器且 AMC 模块较多的复杂通信系统。MTCA PSU 600 为 12 个 AMC、2 个冷却单元 (CU) 和 2 个 MicroTCA 承载集线器 (MCH) 提供所需的独立电源输入。

认证



功能

双高度全尺寸宽度

产品属性

产品类型: 电源

类型: 19" 开关模式

搭配: MicroTCA 系统

交流输入电压: 90 – 264V

电源: 600W

输出电压数: 2

电压 1: 12V

电流 1: 6.8A
电压 2: 3.3V
电流 2: 0.18A
机架宽度: 6HP
深度: 186.65mm
高度: 148.3mm
包装数量: 1

其他产品详情

输出 数据 在下述环境下测得：Ta = - 25 ... 55 °C 且风量为 20 cfm 。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE