


适用 CompactPCI 的 PSU 19", AC/DC, 6 U, 8 HP

物料号

13100-145

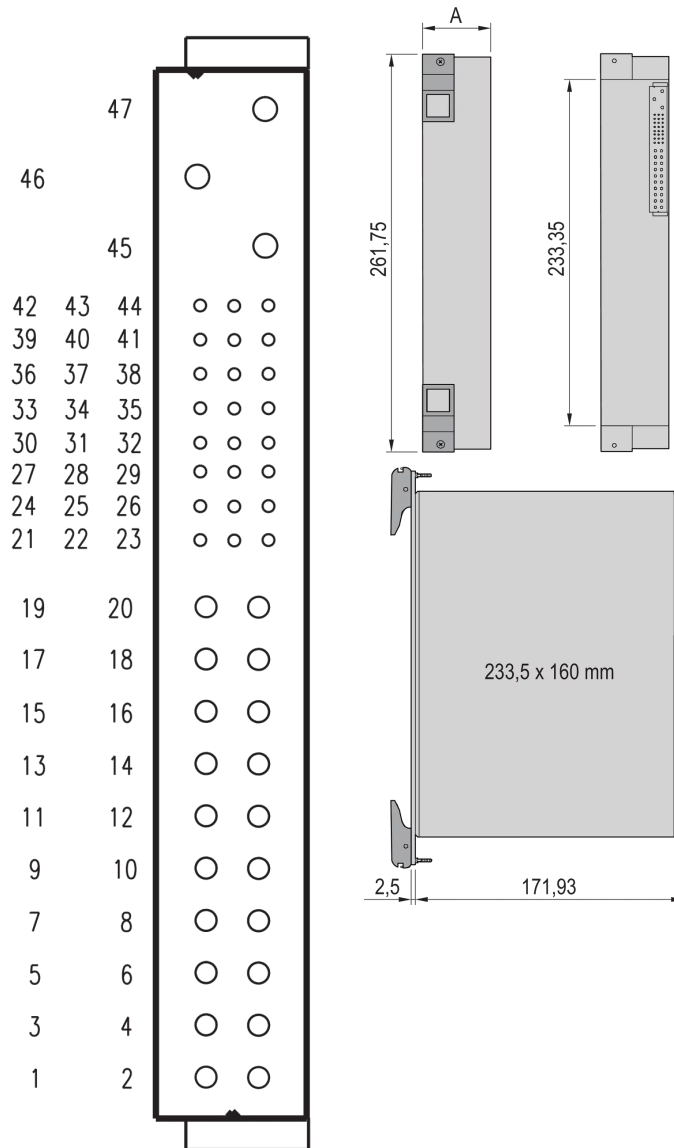

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

认证



功能

P47 连接器和 CompactPCI 信号
4 种输出电压
带有均流总线 (CSB) 的冗余运行, 热插拔

产品属性

产品类型: 电源
类型: 19" 开关模式
搭配: CompactPCI 和 VME64x
交流输入电压: 90 – 264V
电源: 500W
输出电压数: 4
电压 1: 5V
电流 1: 50A
电压 2: 3.3V
电流 2: 60A
电压 3: 12V
电流 3: 12A
电压 4: -12V
电流 4: 4A
机架高度: 6U
机架宽度: 8HP
深度: 171.93mm
Net Weight: 1.5kg
包装数量: 1

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE