


PSU 19 英寸 AC/DC 最大功率 180 W，单输出，最大 112

物料号

13100-151

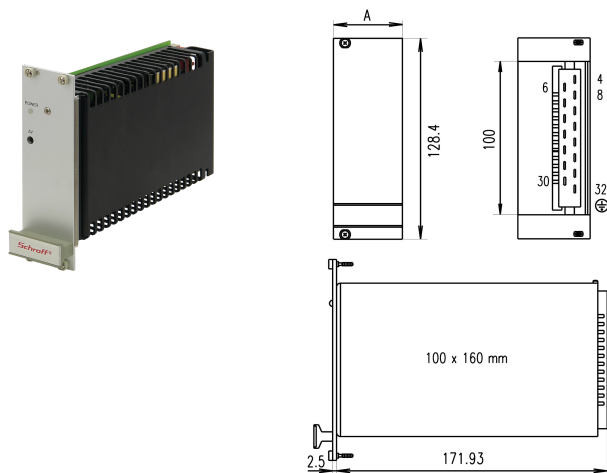

Pluggable 19" Power Supplies with H15 connector for fanless applications. 支持宽幅 交流输入和一路输出电压。

认证



功能

宽幅电压输入 90 ... 254 VAC 和 100 ... 360 VDC，带有源功率因数校正 (PFC)

1 输出电压

电源信号：输出电压正常

效率高达 87%

集成有源去耦元素，用于支持电源冗余配置

产品属性

产品类型: 电源
类型: 19" 开关模式
交流输入电压: 90 – 264V
电源: 156W
输出电压数: 1
电压 1: 12V
电流 1: 13A
机架高度: 3U
机架宽度: 8HP
包装数量: 1

其他产品详情

请单独订购前面板。

电源电压 > 190 VAC 且 TA = 0 ... 时的输出数据50 °C。

警告

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE