


PSU 19 英寸 AC/DC 线性稳压器，单，PSK 112

物料号

13105-002

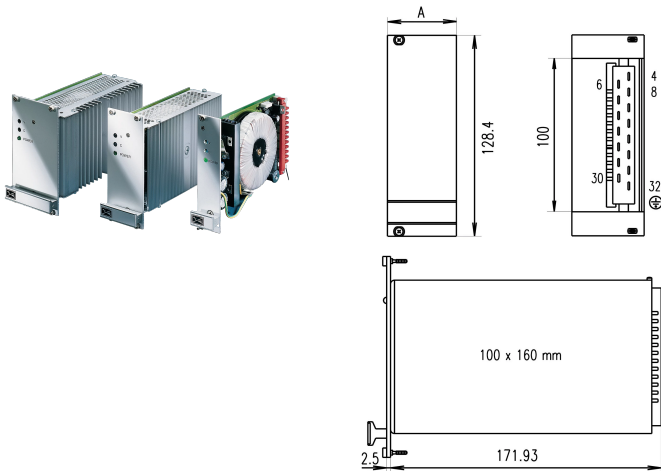

线性稳压器，适用需要极低输出噪音水平的应用。

认证



功能

1 输出电压

控制精度高, 残余纹波低且干扰低

230 VAC 电源/线路电压 (可通过电源/线路电压转换套件转换为 115 VAC 电压输入)

适用医疗应用 (8 mm安全间隙)

产品属性

产品类型: 电源

类型: 19" 线性稳压器
交流输入电压: 230V
电源: 13W
输出电压数: 1
电压 1: 12V
电流 1: 1.1A
机架高度: 3U
机架宽度: 6HP
深度: 171.93mm
Gross Weight: 0.8kg
包装数量: 1

其他产品详情

请单独订购前面板。

输出数据是在Ta = 0 ... 50 °C 环境下测得。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE