


## 轻型通用型伸缩滑轨，2 U，356L

物料号

**20110-071**

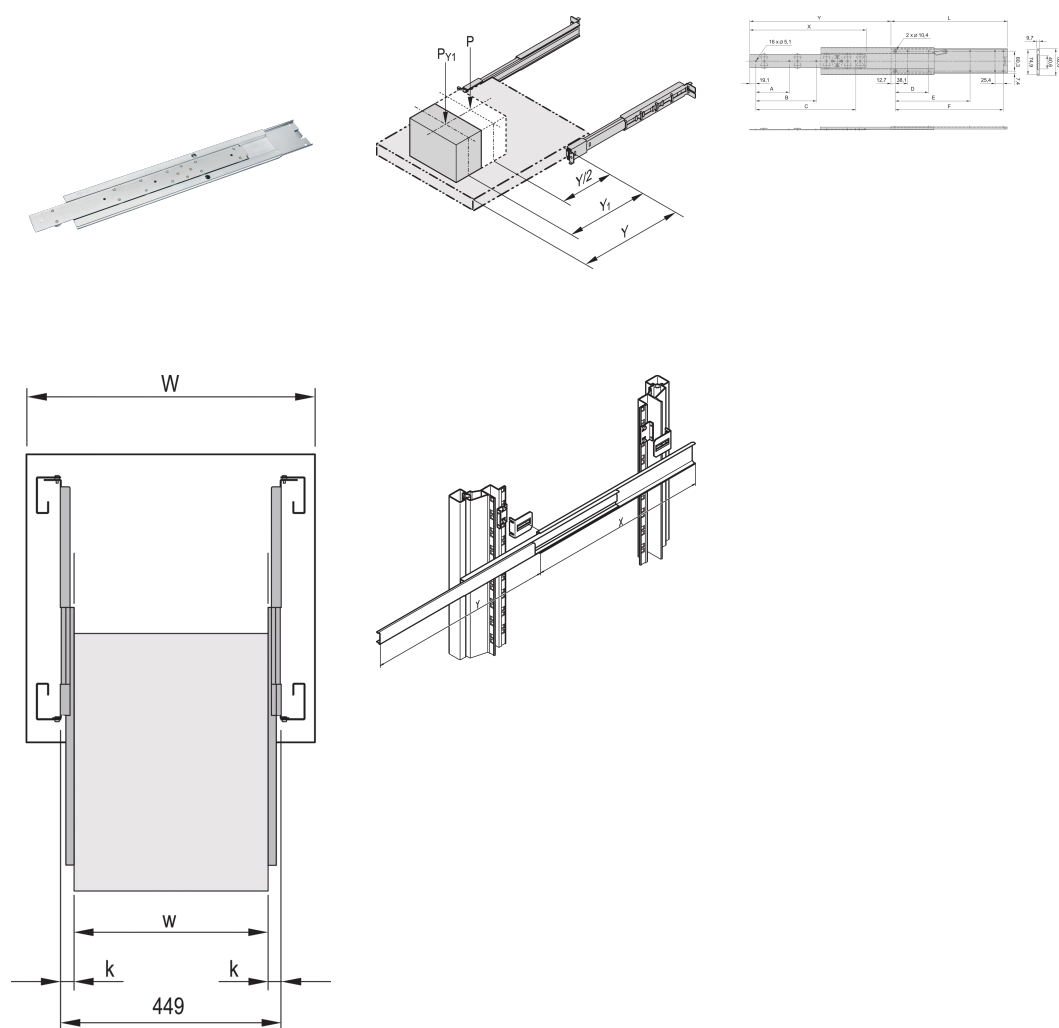

轻型通用型伸缩滑轨，2 U。

## 认证

功能

|                                           |
|-------------------------------------------|
| 轨道宽度 k = 9.7 mm, 延长部件/抽屉最大安装宽度 w = 429 mm |
| 在 19" 支柱上横向安装（不占用 19" 平面即可安装延长部件/抽屉）      |
| 全延长状态下可锁定                                 |
| 静态承载能力每对 46 - 57 千克                       |
| 延长宽度 > 110 %                              |

产品属性

|                     |
|---------------------|
| 长度: 356mm           |
| 包装数量: 2             |
| 完成: 镀锌              |
| 材料: 钢               |
| 产品系列: MultipacPRO   |
| 产品类型: 伸缩滑轨          |
| 静态负载: 57kg          |
| 类型: 通用型             |
| Net Weight: 2.195kg |

其他产品详情

在非标准应用中，无需附加组件也可安装通用伸缩滑轨，除 19" 机柜外也是如此。

要在 19" 面板上安装，请单独订购装配套件。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**