


通用伸缩滑轨，2 U，2 U 356L

物料号

20110-101

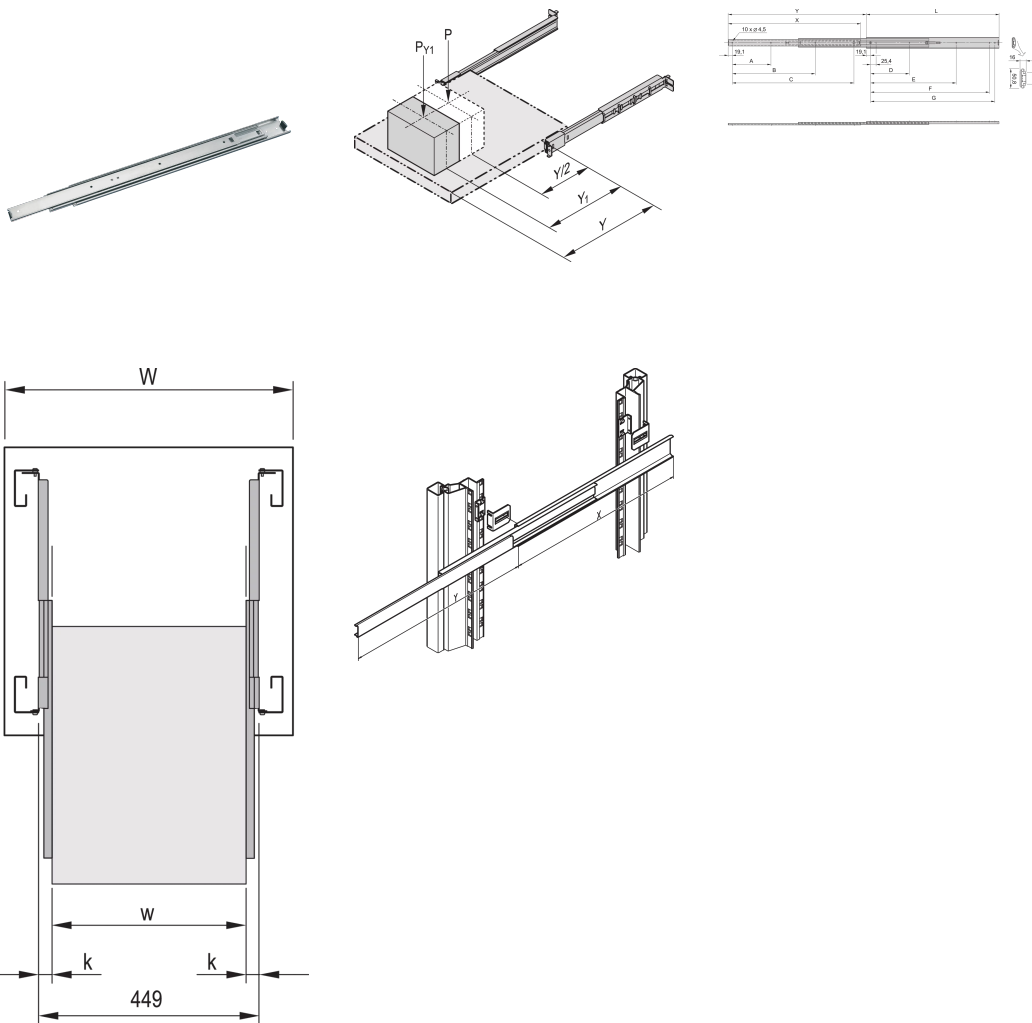

通用伸缩滑轨，延长率 > 100 %，承载能力高达 61 kg。

认证



功能

轨道宽度 k = 16 mm, 延长部件/抽屉最大安装宽度 w = 417 mm
在 19" 立柱上横向安装（19" 平面保持不占用，用于安装延长部件/抽屉）
全延长状态下可锁定
延长宽度 > 100 %
静态承载能力每对 46 - 61 千克

产品属性

长度: 356mm
包装数量: 2
完成: 镀锌
材料: 钢
产品类型: 伸缩滑轨
静态负载: 60kg
类型: 通用型
Net Weight: 1.625kg

其他产品详情

要安装于 19" 面板上，请单独订购装配套件。通用伸缩滑轨也可以在没有附加组件的情况下安装在非标准应用中，因此也适用于 19" 机柜以外的机柜。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE