


IEL 型助插器/助拔器把手， IEL 型， 黑色手柄， 灰色按钮， 底部， 100 个

 
物料号

20817-683

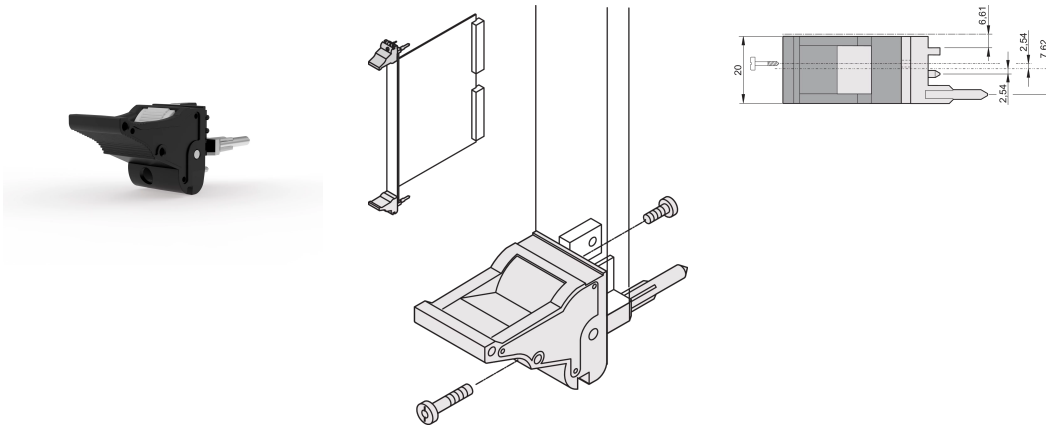

助拔器把手， IEL 型， 符合 IEEE 1101.10 标准。 0,1" 偏移。 其中两个把手可以克服 700N 的单杠杆力（每对）。

认证



功能

插入和拔出力高达 700 N（每对）

符合 IEEE 1101.10 和 IEC 60297-3-102 标准

可安装微型开关

0.1" 偏移用于带背板贴片的电源模块

产品属性

包装数量: 100

手柄类型: IEL; 底部前部

可燃性等级: UL® 94V-0

颜色: 黑色

符合: EN 45545-2

材料: 聚碳酸酯; 锌合金

产品类型: 手柄

类型: 助插器/助拔器, 0.1" 偏移


搭配: 前面板

Net Weight: 2.43kg

其他产品详情

请单独订购编码键和微型开关。

图

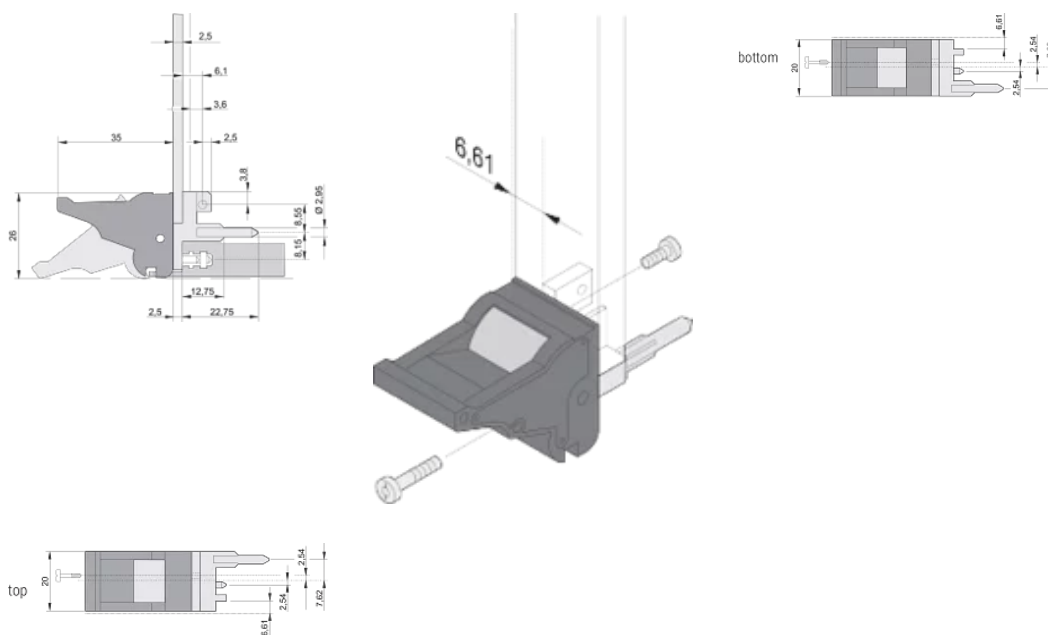

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE