


IET 型助插器/助拔器把手，IET 型，黑色手柄，灰色按钮，顶部；10 个

物料号

20817-708

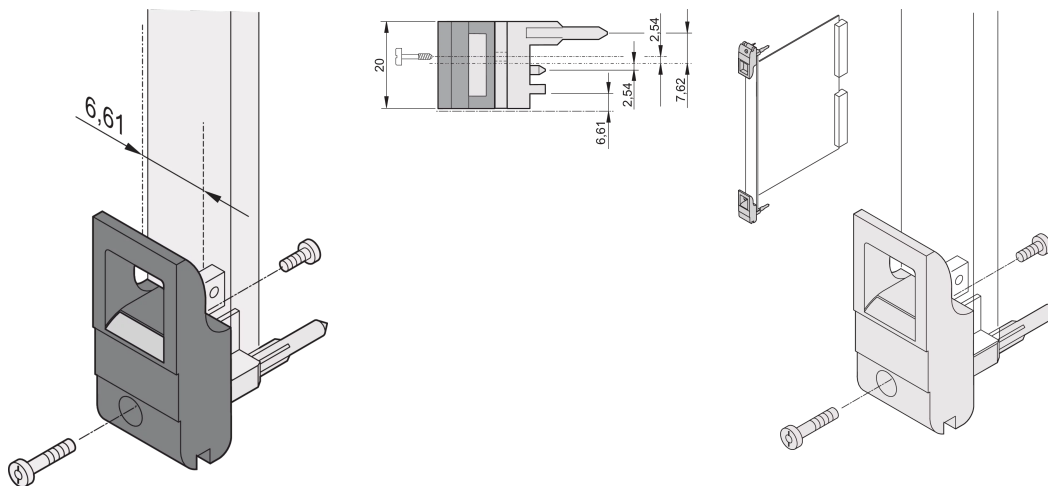

助插器/助拔器把手，IET 型，符合 IEEE 1101.10 标准。0,1" 偏移。其中两个把手可以提供 700 N 的单杠杆力（每对）。

认证



功能

插入和拔出力高达 700 N（每对）

符合 IEEE 1101.10 和 IEC 60297-3-102 标准

可安装微型开关

0.1" 偏移用于带 背板贴片的 电源模块


产品属性

包装数量: 10
手柄类型: IET; 顶部前部
可燃性等级: UL® 94V-0
颜色: 墨黑色
颜色代码: RAL 9005
符合: EN 45545-2
深度 (D): 39.15mm
高度 (H): 44.65mm
材料: 聚碳酸酯; 锌合金
产品类型: 手柄
类型: 助插器/助拔器, 0.1" 偏移
宽度 (W): 19.8mm
搭配: 前面板
Net Weight: 0.24kg

其他产品详情

请单独订购编码键和微型开关。

图

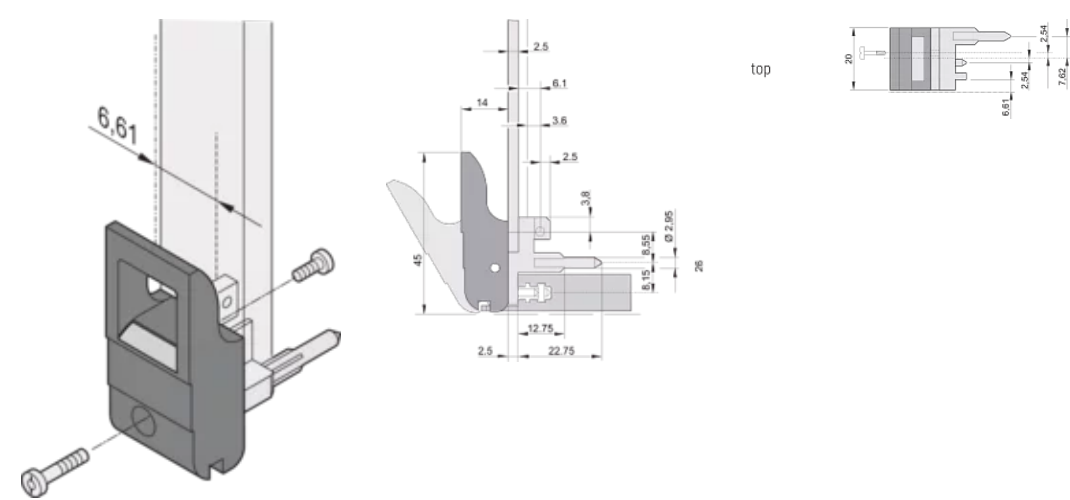

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE