


# IET 型助插器/助拔器把手，IEL 型，灰色手柄，黑色按钮，顶部，100 个

物料号

**20817-717**

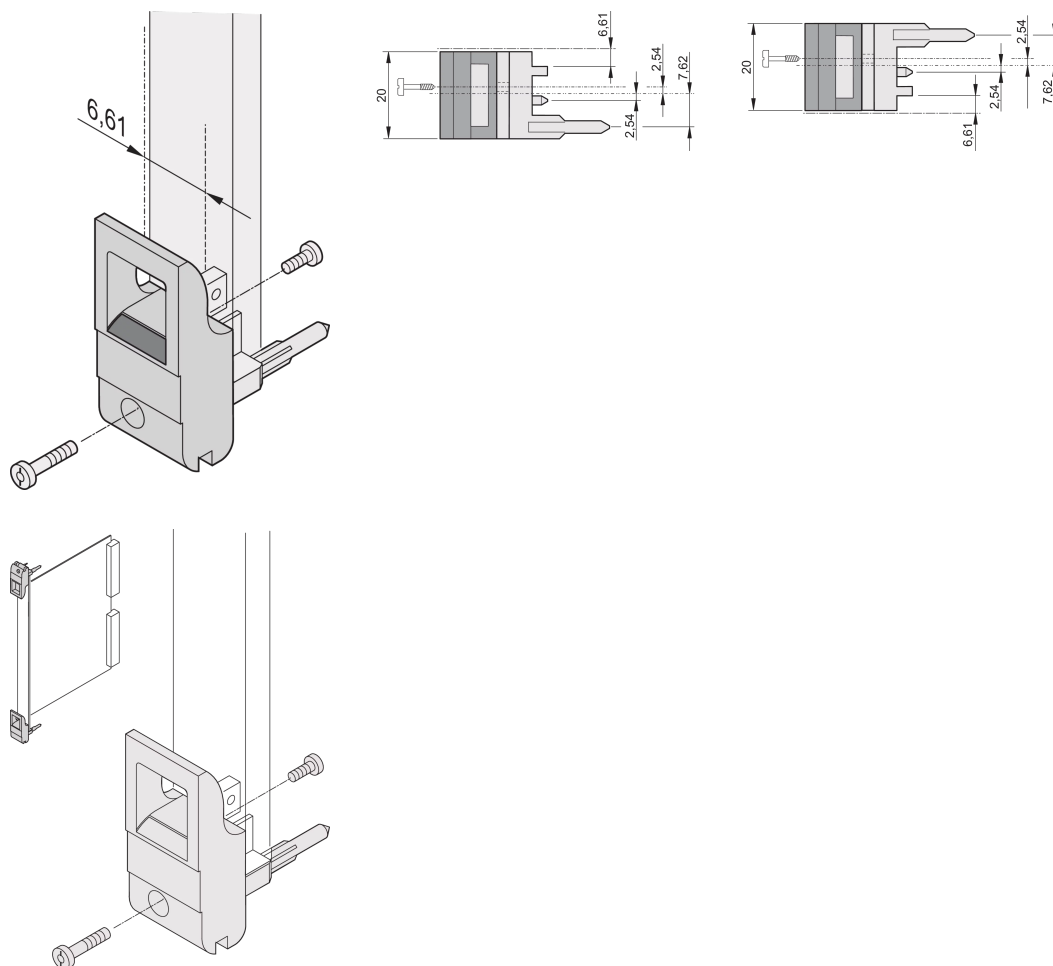

助插器/助拔器把手，IET 型，符合 IEEE 1101.10 标准。0,1" 偏移。其中两个把手可以提供 700 N 的单杠杆力（每对）。

认证



功能

- 插入和拔出力高达 700 N（每对）
- 符合 IEEE 1101.10 和 IEC 60297-3-102 标准
- 可安装微型开关
- 0.1" 偏移用于带 背板贴片的 电源模块


产品属性

- 包装数量: 100
- 手柄类型: IET; 顶部前部
- 可燃性等级: UL® 94V-0
- 颜色: 灰色
- 材料: 聚碳酸酯
- 产品类型: 手柄
- 类型: 助插器/助拔器，0.1" 偏移
- 搭配: 前面板
- Net Weight: 2.28kg

其他产品详情

请单独订购编码键和微型开关。

图

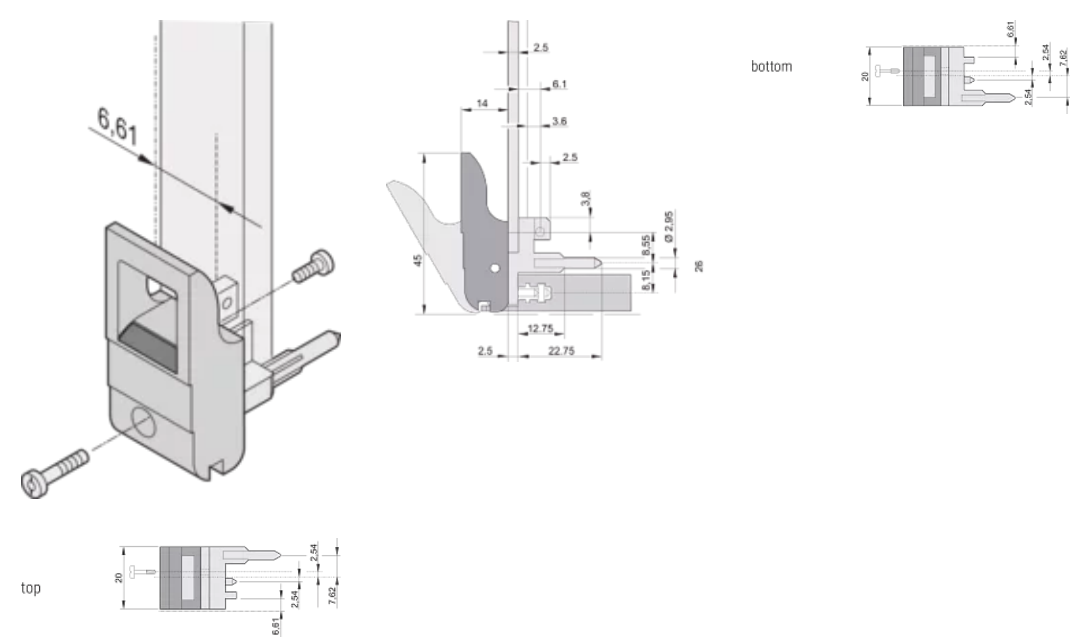

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE