


# 适用 XL 把手面板套件的微动开关，带电缆和插头

## 物料号

**20817-877**

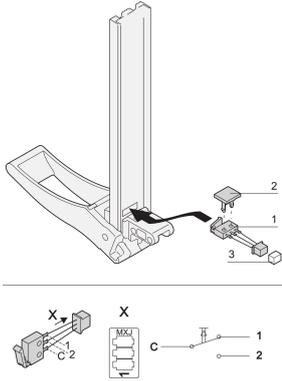

适用于 XL 前面板的微型开关。

## 认证



## 功能

电气寿命  $\geq 20,000$  开关

塑料, PC, UL 94 V-0

Molex 连接器

与之配合的连接器不包括在交付范围内

机械寿命  $\geq 20,000$  切换周期

工作范围  $-25\text{ }^{\circ}\text{C}$  至  $+70\text{ }^{\circ}\text{C}$

XL 把手微型开关

最大开关电流 50 mA

Molex 挤压触点和固定夹

## 产品属性

产品类型: 开关

搭配: 前面板

包装数量: 10

深度: 35.59mm

Gross Weight: 0.012kg

高度: 8.2mm

材料: 聚对苯二甲酸丁二醇酯

宽度: 7.84mm

## 其他产品详情

交付中未包含配合连接器。Molex 的配合连接器，例如 53261-0319、53048-0310、53047-0310、53398-0319、51047 - 0300。

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**