


PMC 夹层卡前面板，未处理，带 EMC 屏蔽，铝，阳极氧化，1 个

物料号

20835-598

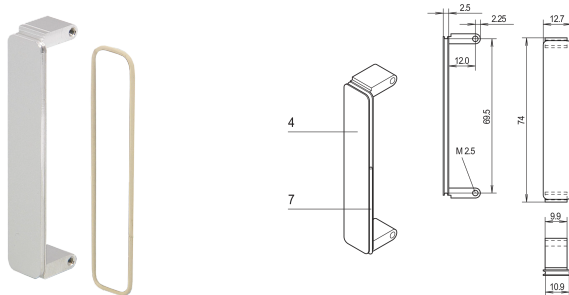

夹层前面板安装在 PMC 前面板开孔中。提供不同处理方式的版本。适用于 O 形环 EMC 垫片。

认证



功能

夹层前面板安装在带 PMC 开孔的前面板中

EMC 屏蔽，带导电 O 型圈

产品属性

包装数量: 1

附件类型: 前面板

安装: 正面螺钉安装

垫片类型: O 形环 EMC

正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
符合: PMC 夹层板, IEEE P1386
深度: 2.5mm
EMC 屏蔽: 是
完成: 阳极氧化
高度: 74mm
材料: 铝
产品类型: 前面板
类型: 不带把手的前面板
宽度: 12.7mm
Net Weight: 0.015kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE