


适于 FMC 夹层前面板开孔的边框，VITA 57.1

物料号

20835-849

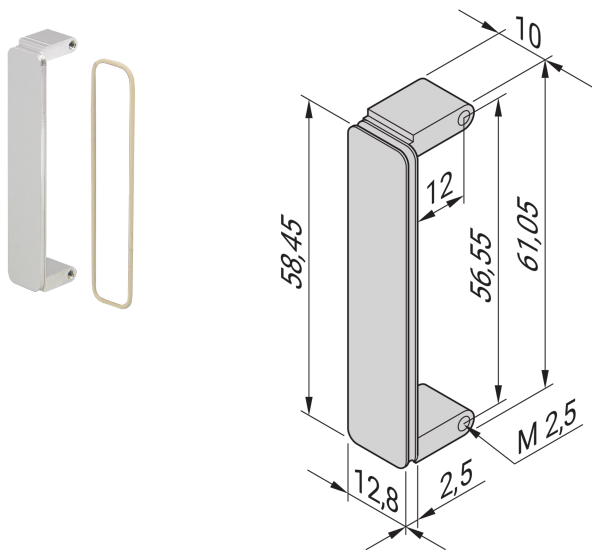

FMC面板安装在支持 FMC 夹层卡开孔的前面板中，10 个 FMC 面板组成的套件。

认证



功能

FMC 面板可以安装在支持 FMC 夹层板开孔的前面板中

FMC面板可以选择使用导电 O 形圈屏蔽, 请单独订购

材料, 铝挤压件 (阳极氧化, 表面导电)

产品属性

产品类型: 前面板

类型: 夹层前面板

附件类型: 前面板

安装: 卡扣嵌入式

EMC 屏蔽: 无 (可改装)

EMC 垫片类型: O 形环

材料: 铝

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

高度: 58.45mm

宽度: 12.8mm

深度: 2.5mm

符合: FMC Mezzanine; IEEE P1386

包装数量: 10

完成: 阳极氧化

Net Weight: 0.1kg

其他产品详情

请单独订购 EMC O 形圈。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE