


带 IEL 把手的 FMC 插入式单元套件，黑色，U 形前面板屏蔽（泡棉），6 U，4 HP

物料号

20836-254

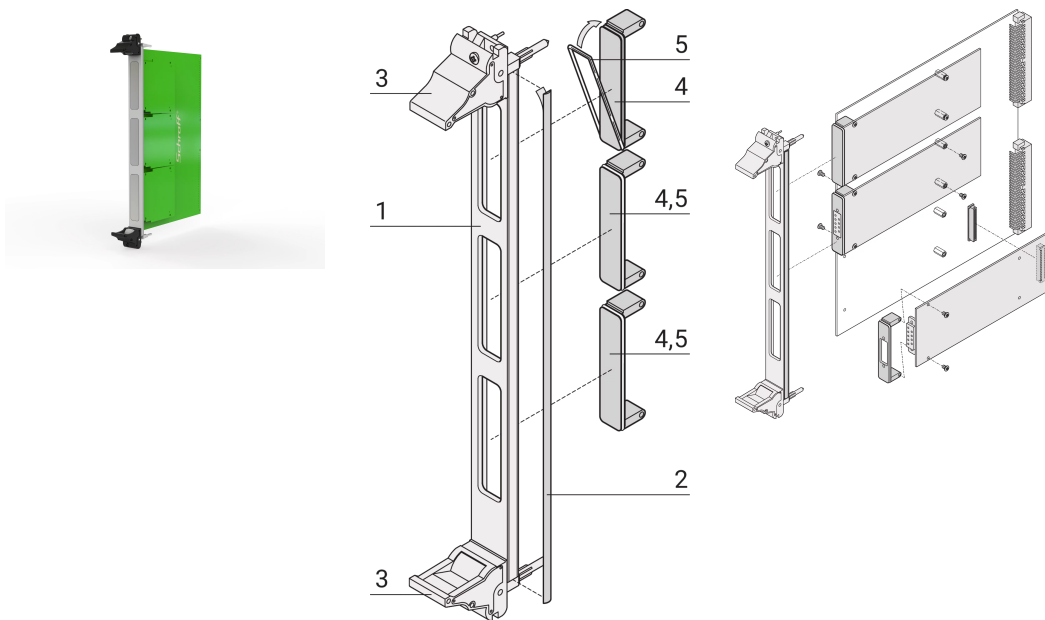

FMC 面板符合 Vita 57.1 规范。覆盖整个前面板上的开孔。

认证



功能

符合 Vita 57.1 技术参数

适用于单个 69.0 x 76.5 mm 模块或两个 139.0 x 76.5 mm 模块

带有 IEL 把手的铝型材面板

产品属性

机架高度: 6U

包装数量: 1

手柄类型: IEL

安装: 正面螺钉安装

EMC 垫片类型: 织物

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

符合: FMC 夹层板, Vita 57.1

EMC 屏蔽: 是

完成: 阳极氧化; 钝化

高度: 261.8mm

材料: 铝

产品类型: 前面板

机架宽度: 4HP

类型: 带把手的前面板 (PIU)

宽度: 20mm

Net Weight: 0.15kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte