


HF 框架型插入装置前面板, 3 U, 7 HP, 2.5 毫米, 铝, 前部经阳极氧化, 后部导电

物料号

20838-001

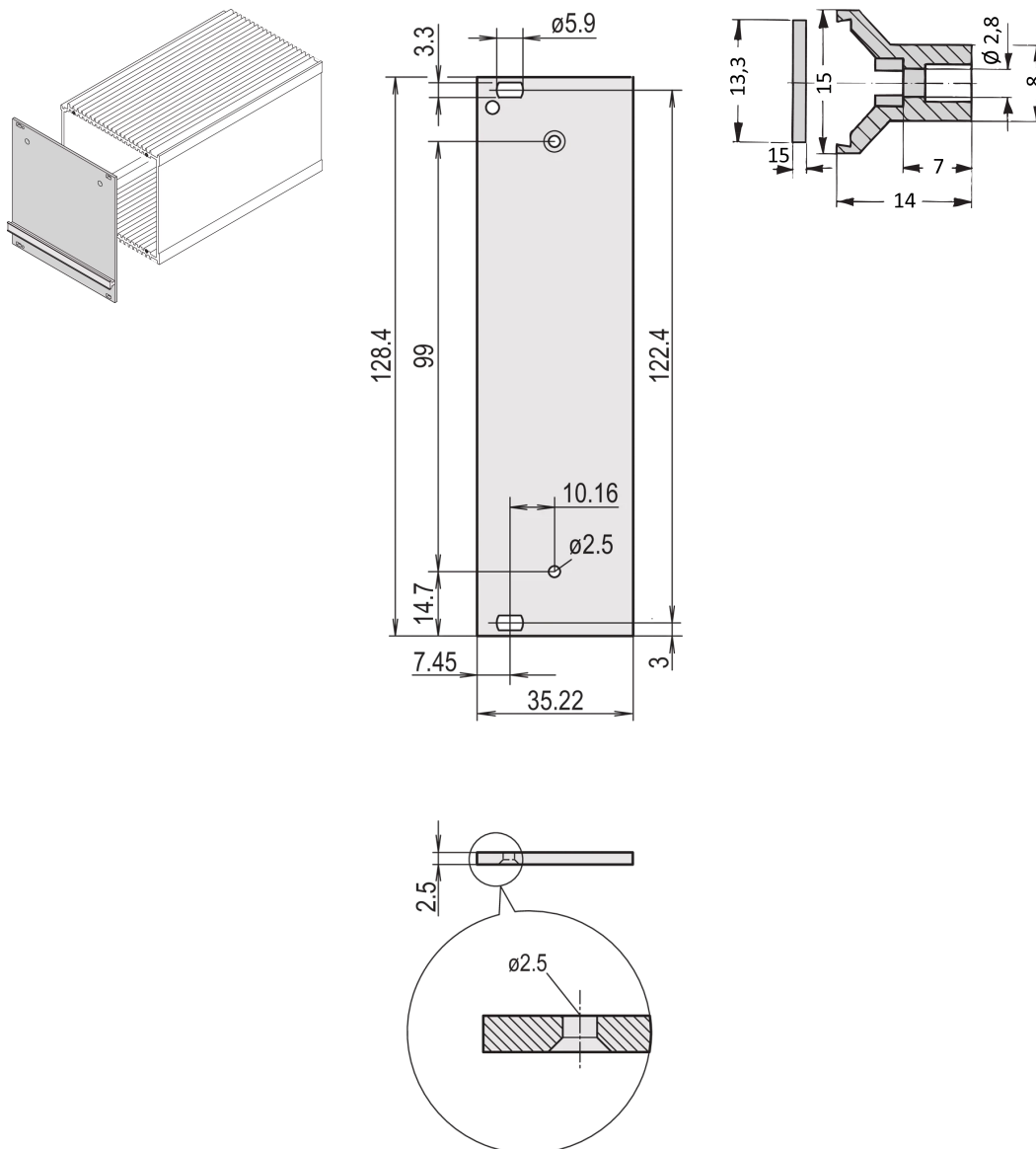

铝2.5正面阳极氧化, 高频盒导电无屏蔽。用于塑料前把手。



功能

铝, 2.5 mm, 正面阳极氧化, conductive; trapezium shaped handle, 灰色, PPE, UL 94 V-1


带把手的前面板可通过螺栓固定在 HF 插插件上

产品属性

- 机架宽度: 7HP
- 包装数量: 1
- 附件类型: 前面板
- 正面表面处理: 阳极氧化
- 反面表面处理: 导电
- 边缘处理: 否
- 深度 (D): 2.5mm
- 完成: 阳极氧化; 钝化
- 高度 (H): 128.4mm
- 材料: 铝
- 产品类型: 前面板
- 机架高度: 3U
- 宽度 (W): 32.22mm
- Net Weight: 0.035kg

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

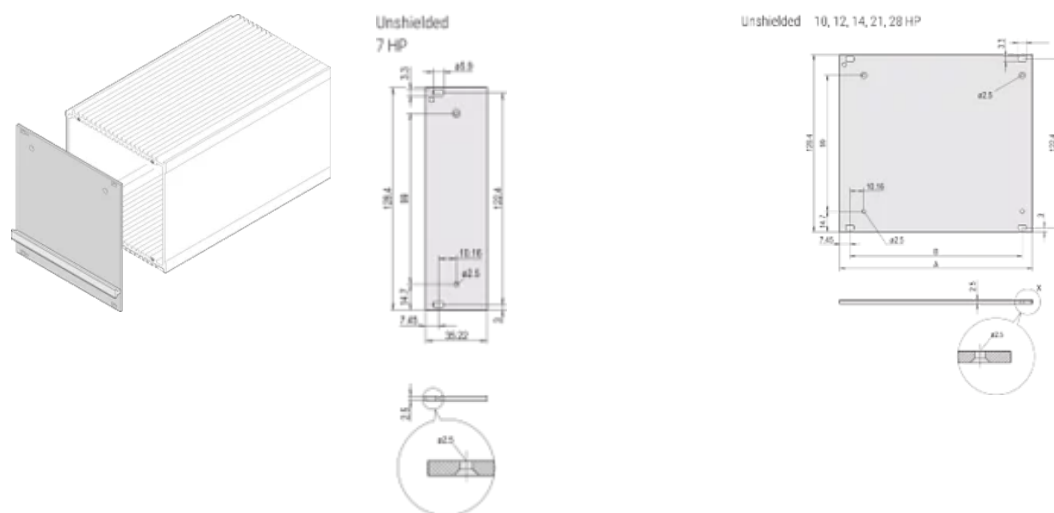

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE