


HF 框架型插入装置前面板，3 U，12 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

20838-003

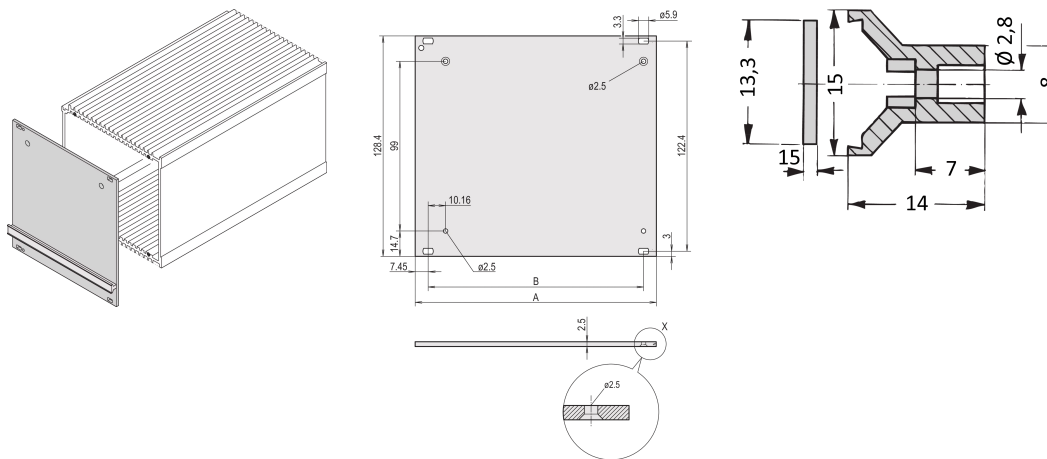

铝2.5正面阳极氧化，高频盒导电无屏蔽。用于塑料前把手。

认证



功能

铝, 2.5 mm, 正面阳极氧化, conductive; trapezium shaped handle, 灰色, PPE, UL 94 V-1

带把手的前面板可通过螺栓固定在 HF 插插件上

产品属性

机架宽度: 12HP

包装数量: 1

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE