


HF

框架型插入装置前面板，改进屏蔽型，带钢垫片，3 U，21 HP

物料号

20838-097

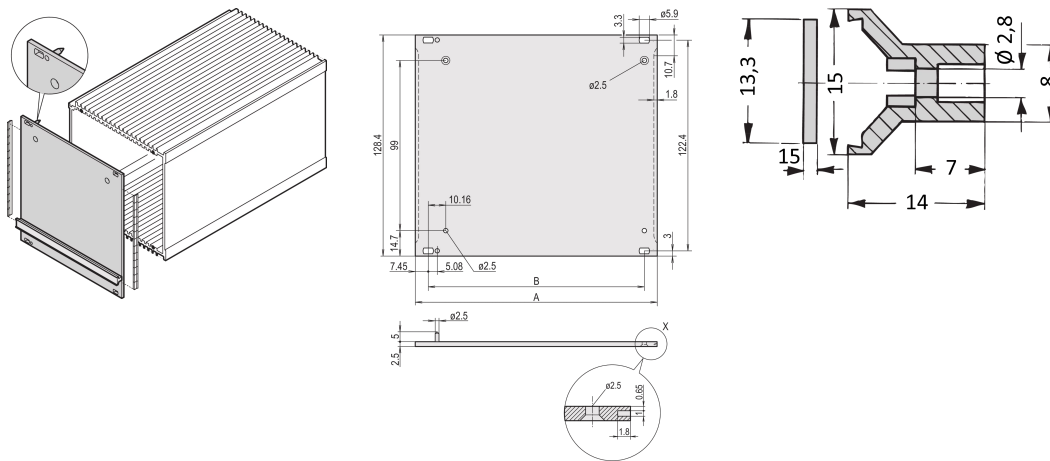

铝, 2.5mm, 前阳极氧化, 后导电, 带侧槽, 用于不锈钢垫片, (请单独订购), 压入定位销; 梯形手柄, 灰色, PPE, UL9 4V-1

认证



功能

铝, 2.5 mm, 正面阳极氧化, 背面导电, 带 EMC 不锈钢垫片的侧向插槽 (请单独订购), pressed-in alignment pin; trapezium shaped handle, 灰色, PPE, UL 94 V-1

带把手的前面板可通过螺栓固定在 HF 插插件上


产品属性

机架宽度: 21HP
包装数量: 1
完成: 阳极氧化; 钝化
材料: 铝
产品类型: 侧面板
机架高度: 3U
类型: 前面板
Gross Weight: 0.114kg

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

图

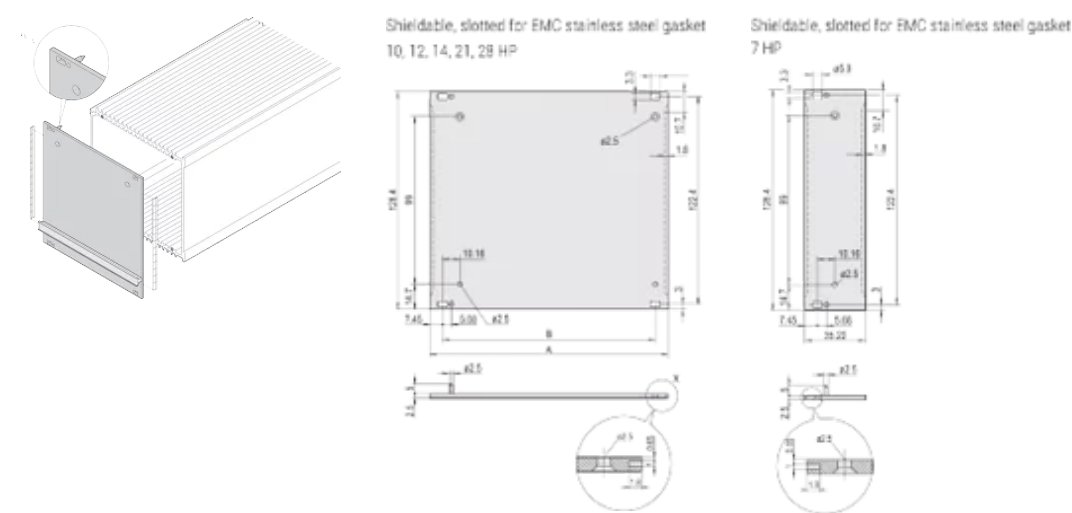

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE