


前面板，U 型，改进屏蔽型，3 U，28 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

20848-027

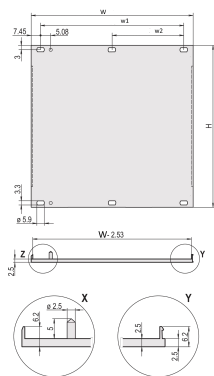

U型前面板，适用泡棉垫片

认证



功能

U 型, 前面板, 铝, 2.5 mm, 正面阳极氧化, 背面导电

适用 EMC 织物垫片

产品属性

机架高度: 3U

机架宽度: 28HP

包装数量: 1

附件类型: 前面板

安装: 正面螺钉安装

EMC 垫片类型: 织物 EMC

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

符合: IEC 60297-3-101; IEEE 1101.1/10

深度 (D): 2.5mm

EMC 屏蔽: 无 (可改装)

完成: 阳极氧化; 钝化

高度 (H): 128.4mm

材料: 铝

产品类型: 前面板

类型: 不带把手的前面板

宽度 (W): 141.9mm

Net Weight: 0.12kg

其他产品详情

请单独订购紧固零件 (螺钉套, 凸缘螺钉)。


2 ... 12 HP 和 14 ... 84 HP 之间外观面差异。

2 ...12 HP: 单部件U型

请单独订购 EMC 泡棉垫片。

Standard pack quantity: 2 to 28HP: 5 件, 42 to 84 HP: 1 件, supplied in standard pack quantities (SPQ) only.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).

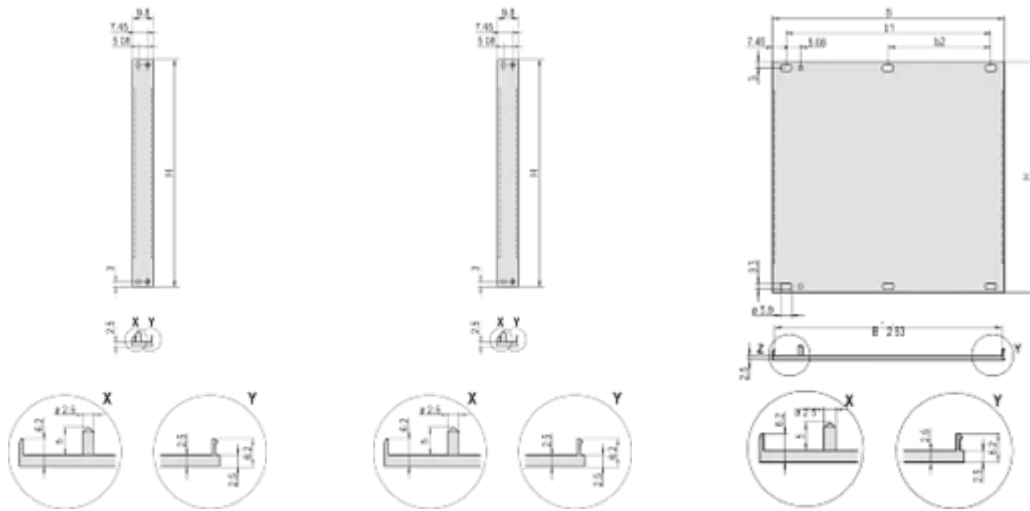

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE