


# 面板套件，带 IEL 把手，屏蔽，黑色 3 U，8 HP

物料号

**20848-589**

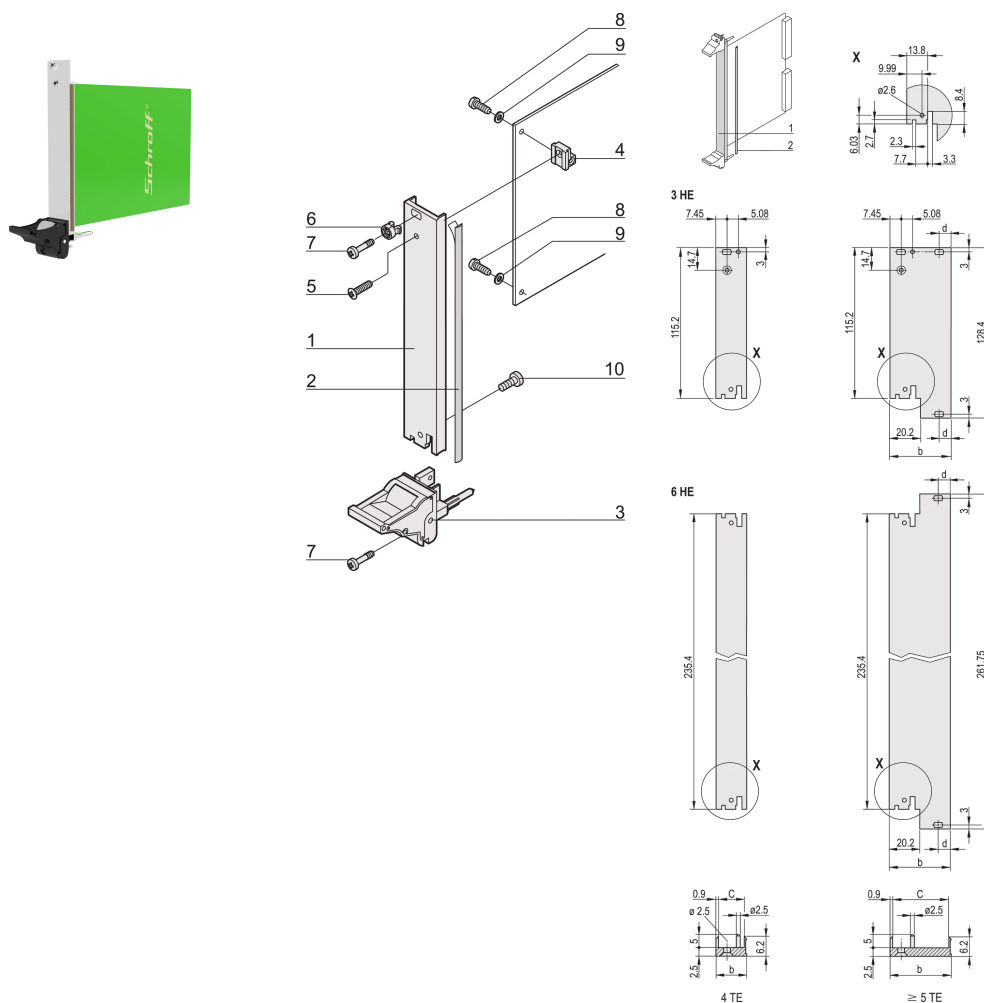

面板套件，带 IEL 助拔器黑色把手，3 U，前组件。U 型前面板带 EMC 导电布屏蔽条

认证



## 功能

带EMC导电布屏蔽条的 U 型前面板

可承受高达 700 N 的插入力和拔出力（每对）

可安装微型开关

可根据 IEC 60297-3-103/IEEE 1101.10 标准安装编码键

## 产品属性

机架宽度: 8HP

包装数量: 1

手柄类型: IEL

安装: 正面螺钉安装

垫片类型: 织物 EMC

正面表面处理: 阳极氧化

反面表面处理: 碱蚀

边缘处理: 否

符合: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11

EMC 屏蔽: 是

完成: 阳极氧化; 钝化

高度 (H): 128.4mm

材料: 铝


产品类型: 前面板

机架高度: 3U

类型: 带把手的前面板 (PIU)

宽度 (W): 40.3mm

Net Weight: 0.1kg

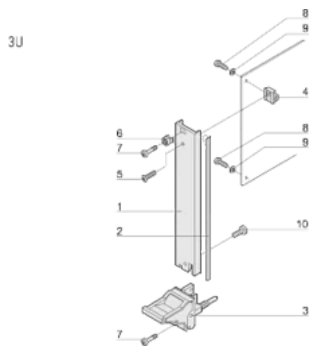

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**