 
 
 

 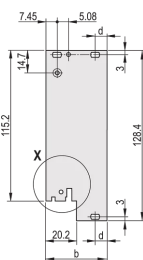

 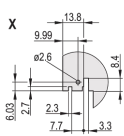

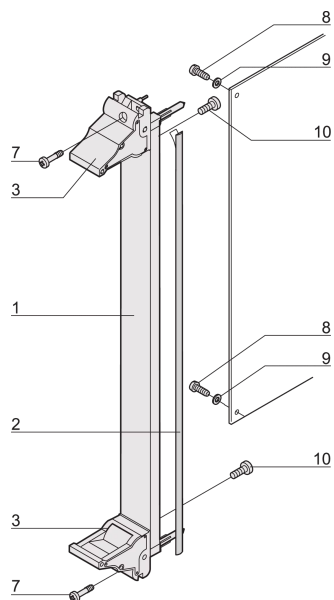


带 IEL 把手的面板套件，屏蔽，黑色，6 U，10 HP

物料号

20848-597

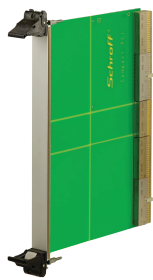

面板套件，带 IEL 助拔器黑色把手，6 U，前组件。U 型前面板带 EMC 导电布屏蔽条

认证




功能

带EMC导电布屏蔽条的 U 型前面板
可承受高达 700 N 的插入力和拔出力（每对）
可安装微型开关
可根据 IEC 60297-3-103/IEEE 1101.10 标准安装编码键

产品属性

机架宽度: 10HP
包装数量: 1
手柄类型: IEL
安装: 正面螺钉安装; 背面螺钉安装 IO
EMC 垫片类型: 织物
正面表面处理: 阳极氧化
反面表面处理: 碱蚀
边缘处理: 否
符合: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11
EMC 屏蔽: 是
完成: 阳极氧化; 钝化
高度 (H): 261.8mm
材料: 铝
产品类型: 前面板
机架高度: 6U
类型: 带把手的前面板 (PIU)
宽度 (W): 50.5mm
Net Weight: 0.19kg

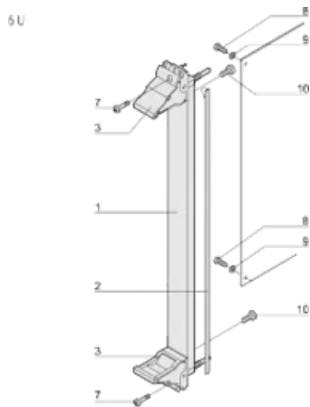

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE