

# 前面板套件，屏蔽，底部铰链，3 U，84 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

## 物料号

**20848-601**



U 型底部铰链固定前面板，用于织物垫片。

## 认证



## 功能

可在 135° 开口角度取下 U 型前面板的铰链（非 RatiopacPRO）

可以安装在水平轨道上

屏蔽型, U型前面板, 带织物垫片

适用于插槽 (EuropacPRO) 和机箱 (RatiopacPRO), PropacPRO, CompacPRO)

## 产品属性

机架高度: 3U

附件类型: 前面板

机架宽度: 84HP

包装数量: 1

安装: 铰链式, 底部

EMC 垫片类型: Textile

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

符合: IEC 60297-3-101; IEEE 1101.1/10

深度 (D): 2.5mm

EMC 屏蔽: 无 (可改装)

完成: 阳极氧化; 钝化

高度 (H): 128.4mm

材料: 铝

产品类型: 前面板

类型: 不带把手的前面板

宽度 (W): 426.4mm

Gross Weight: 0.546kg


## 其他产品详情

---

可在打开位置 (> 135°) 拆卸前面板。

## 图

---

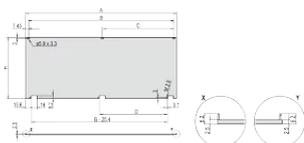

## 警告

---

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**