

前面板套件，屏蔽，底部铰链，4 U，84 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

20848-607



U 型底部铰链固定前面板，用于织物垫片。

认证



功能

可在 135° 开口角度取下 U 型前面板的铰链（非 RatiopacPRO）

可以安装在水平轨道上

屏蔽型, U型前面板，带织物垫片

适用于插槽 (EuropacPRO) 和机箱 (RatiopacPRO), PropacPRO, CompacPRO)

产品属性

机架高度: 4U

附件类型: 前面板

机架宽度: 84HP

包装数量: 1

安装: 铰链式, 底部

EMC 垫片类型: 织物

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

符合: IEC 60297-3-101; IEEE 1101.1/10

深度 (D): 2.5mm

EMC 屏蔽: 无 (可改装)

完成: 阳极氧化; 钝化

高度 (H): 172.9mm

材料: 铝

产品类型: 前面板


类型: 不带把手的前面板

宽度 (W): 426.4mm

其他产品详情

可在打开位置 (> 135°) 拆卸前面板。

图

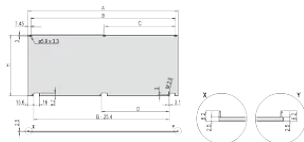

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE