


前面板，屏蔽，侧铰链，3 U，84 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

20848-611

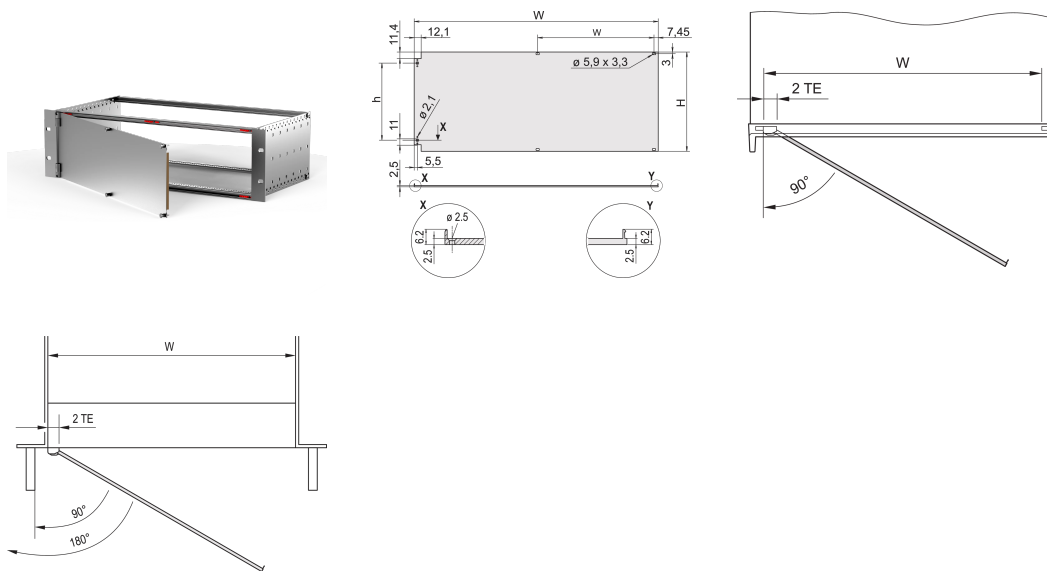

带导电布EMC垫片的面板，侧面铰链固定。

认证



功能

前面板，带纺织物 EMC 垫片

可安装到水平轨道上


适用于插箱和仪器箱

可在左或右安装铰链

产品属性

机架高度: 3U
包装数量: 1
附件类型: 前面板
安装: 铰链式，侧面
EMC 垫片类型: 织物
正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
深度 (D): 2.5mm
EMC 屏蔽: 无（可改装）
完成: 阳极氧化; 钝化
高度 (H): 128.4mm
材料: 铝
产品类型: 前面板
机架宽度: 84HP
类型: 不带把手的前面板
宽度 (W): 426.4mm
Net Weight: 0.56kg

图

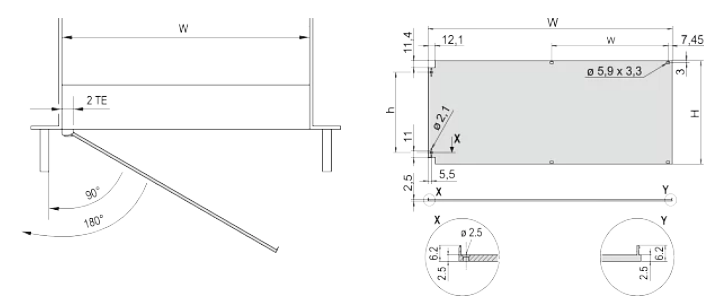

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE