


适用RatiopacPRO/PropacPRO 的后面板，开孔，增强屏蔽，泡棉，6 U，42 HP

物料号

20848-641

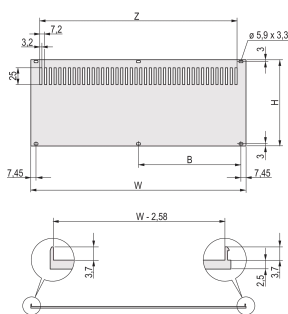

铝制 2.5 mm 网孔后面板为屏蔽型面板。背面具有导电性。

认证



功能

背面板, 铝, 2.5 mm, 前部: 阳极氧化, 后部: 导电; 非屏蔽

可以安装在水平轨道上

产品属性

机架高度: 6U

机架宽度: 42HP

包装数量: 1

完成: 阳极氧化; 钝化

高度: 256mm

材料: 铝
产品系列: RatiopacPRO; RatiopacPRO AIR
产品类型: 侧面板
类型: 背板
宽度: 213mm
搭配: 仪器箱
Gross Weight: 0.399kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE