


面板套件，带 IEL 把手，适于后部 I/O，屏蔽，黑色，3 U，4 HP

物料号

20848-751

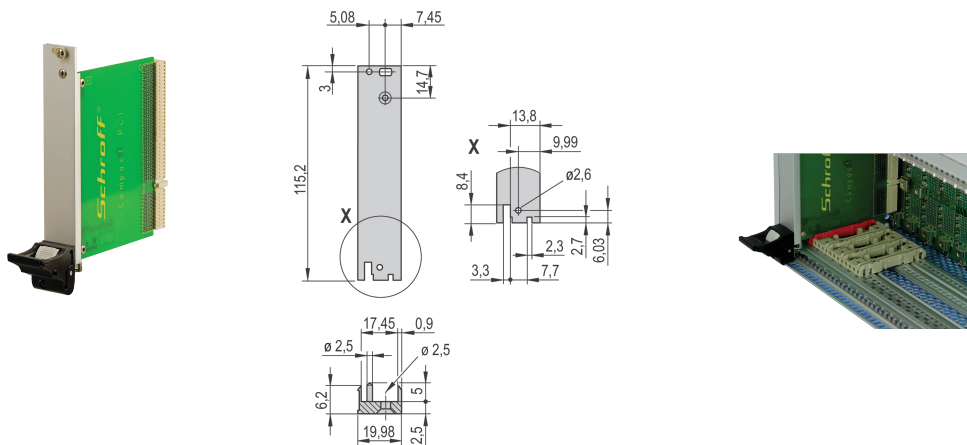

插入装置，带 IEL 助插器/助拔器黑色把手，3 U，后部 I/O 组件。U 型前面板带 EMC 导电布屏蔽条

认证



功能

带 EMC 导电布屏蔽条的 U 型前面板

可承受高达 700 N 的插入力和拔出力（每对）


可安装微型开关

可根据 IEC 60297-3-103/IEEE 1101.10 标准安装编码键

产品属性

机架宽度: 4HP
包装数量: 1
手柄类型: IEL
安装: 背面螺钉安装 IO
垫片类型: 织物 EMC
正面表面处理: 阳极氧化
反面表面处理: 碱蚀
边缘处理: 否
符合: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11
EMC 屏蔽: 是
完成: 阳极氧化; 钝化
高度 (H): 128.4mm
材料: 铝
产品类型: 前面板
机架高度: 3U
类型: 带把手的前面板 (PIU)
宽度 (W): 20mm
Net Weight: 0.08kg

图

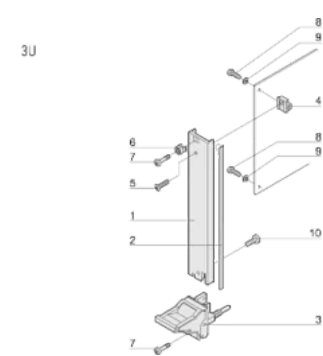

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE