
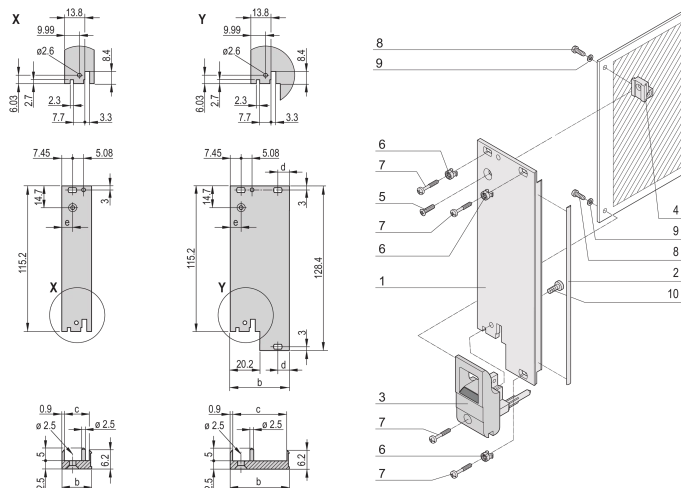


# 模件盒套件，带 IET 把手，屏蔽，黑色 3 U，12 HP

物料号

**20848-765**

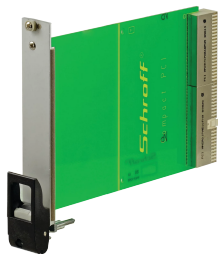

模件盒，带 IET 助插器/助拔器，黑色把手，3 U，前组件。U 型前面板带 EMC 导电布屏蔽条

认证



功能

带 EMC 导电布屏蔽条的 U 型前面板

可承受高达 700 N 的插入力和拔出力（每对）

可安装微型开关

可根据 IEC 60297-3-103/IEEE 1101.10 标准安装编码键

## 产品属性

---

机架宽度: 12HP

包装数量: 1

手柄类型: IET

安装: 正面螺钉安装

垫片类型: 织物 EMC

正面表面处理: 阳极氧化

反面表面处理: 碱蚀

边缘处理: 否

符合: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11

EMC 屏蔽: 是

完成: 阳极氧化; 钝化

高度: 128.4mm

材料: 铝

产品类型: 前面板

机架高度: 3U

类型: 带把手的前面板 (PIU)

宽度: 60.6mm

Net Weight: 0.014kg

## 警告

---

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**